
 
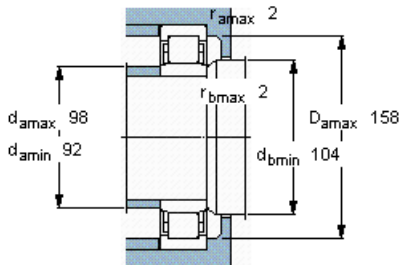



Cylindrical roller bearings, single row



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation	Angle ring Designation
d	D	B	dynamic	static		Reference speed	Limiting speed			
mm			kN	C_0	kN	r/min		kg	-	-
80	170	39	300	290	36	4300	5000	3,95	NU 316 ECP *	HJ 316 EC

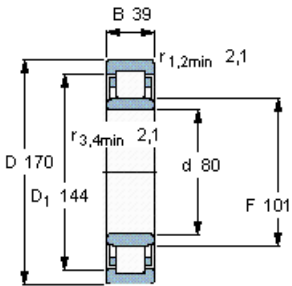

Calculation factors
 k_r 0,15
 e 0,2 γ 0,6

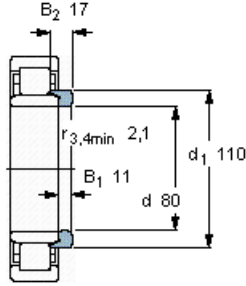

HJ 316 EC
Mass kg 0,44