

Datasheet

RS Unshielded Test Lead Wire 1 mm² CSA 500 V Red PVC Single Core, 199 Strands 5m

RS Stock No. 748-1967



Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Single

Cable Construction

| | |
|------------------------|----------------------|
| Conductor | Bare Copper |
| Cross section | 1.0mm ² |
| Construction(±0.003mm) | 0.08× 199 |
| Standard Dia. | 1.30 |
| Jacket | PVC |
| Thickness | 1.25 |
| Jacket Dia.(mm) | 3.90±0.15 |
| Color | Red(RAL3000): Black; |

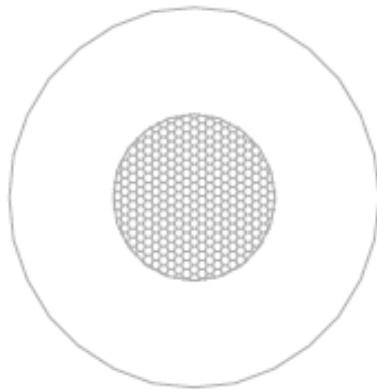
Marking

No Printing

PACKAGING

5M/ plastic Bag

Suitable pieces/Box

**Electrical Characteristics**

| | |
|--|---------|
| Max.Conductor DC Resistance at 20 °C (Ω /Km) | 18.7 |
| Min.Insulation DC Resistance at 20 °C (M Ω *Km) | >500 |
| Rated Temperature(°C) | -20~+80 |
| Rated Voltage (V) | 300/500 |