



MASTER TL-D Secura

MASTER TL-D Secura 58W/840 1SL

Low-pressure mercury discharge lamps with a tubular 26 mm envelope

Product data

• General Characteristics

Cap-Base	G13 [Medium Bi-Pin Fluorescent]
Bulb	T8 [26 mm]
Life to 10% failures EM	12000 hr
Life to 10% fail Preheat EL,3h	17000 hr
Life to 10% fail Nonpreh EL,3h	10000 hr
Life to 50% failures EM	15000 hr
Life to 50% fail Preheat EL,3h	20000 hr
Life to 50% fail Nonpreh EL,3h	12000 hr
LSF EM 2000h Rated, 3h cycle	99 %
LSF EM 4000h Rated, 3h cycle	99 %
LSF EM 6000h Rated, 3h cycle	99 %
LSF EM 8000h Rated, 3h cycle	99 %
LSF EM 12000h Rated,3h cycle	89 %
LSF EM 16000h Rated,3h cycle	33 %
LSF EM 20000h Rated,3h cycle	2 %

• Light Technical Characteristics

Colour Code	840 [CCT of 4000K]
Colour Rendering Index	85 Ra8
Colour Designation	Cool White
Colour Temperature	4000 K

Luminous Flux EM 25°C, Rated	5000 Lm
Luminous Flux EM 25°C, Nominal	5000 Lm
Lum Efficacy Rated EM 25°C	85.5 Lm/W
Average Luminance EM	1.4 cd/cm2
LLMF EM 2000h Rated	96 %
LLMF EM 4000h Rated	95 %
LLMF EM 6000h Rated	94 %
LLMF EM 8000h Rated	93 %
LLMF EM 12000h Rated	92 %
LLMF EM 16000h Rated	91 %
LLMF EM 20000h Rated	90 %
Design Temperature	25 C
Chromaticity Coordinate X	383 -
Chromaticity Coordinate Y	386 -

• Electrical Characteristics

Lamp Wattage	58 W
Lamp Wattage EM 25°C, Nominal	58 W
Lamp Wattage EM 25°C, Rated	58.5 W
Lamp Voltage EM 25°C	111 V

MASTER TL-D Secura

Lamp Current EM 25°C 0.670 A
Dimmable yes

Insertion Length B 1504.7 (min), 1507.1 (max) mm
Overall Length C 1514.2 (max) mm
Diameter D 28 (max) mm

• Environmental Characteristics

Energy Efficiency Label (EEL) A
Mercury (Hg) Content 2.0 mg
Energy consumption kWh/1000h 68 kWh

• UV-related Characteristics

Erythral Radiation <=320nm 0.3 mW
Erythral Radiation >320nm 16 mW
Damage Factor D/fc 0.13 -

• Product Dimensions

Base Face to Base Face A 1500.0 (max) mm

 

• Product Data

Order code 640185 40
Full product code 871150064018540
Full product name MASTER TL-D Secura 58W/840 1SL
Order product name MASTER TL-D Secura 58W/840 1SL/25
Pieces per pack 1
Packing configuration 25
Packs per outerbox 25
Bar code on pack - EAN1 8711500640185
Bar code on outerbox - EAN3 8711500640192
Logistic code(s) - 12NC 927922484076
ILCOS code FD-58/40/1B-E-G13
Net weight per piece 243.100 gr

Warnings and Safety

- Not suitable for closed luminaires (as indicated by two blue rings)

Dimensional drawing

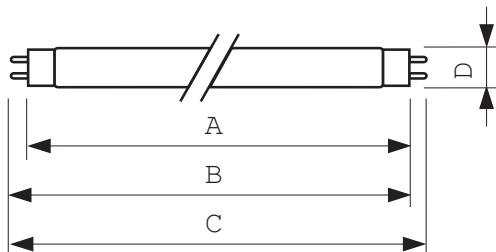



G13

- Recommended use in combination with self-stopping lamp control system

MASTER TL-D Secura 58W/840 1SL

Product	A (Max)	B (Min)	B (Max)	C (Max)	D (Max)
TL-D 58W/840 Secura	1500.0	1504.7	1507.1	1514.2	28

Photometric data

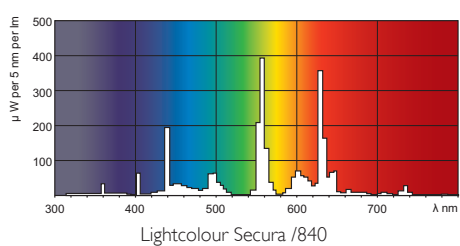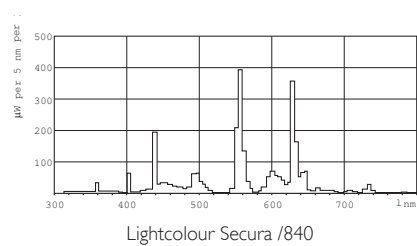

© 2013 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2013, December 17
data subject to change