




ENGLISH

Datasheet

Stock No: 522-484

RS Pro 7 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

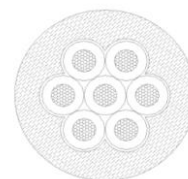

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :

<13.7

Min.Insulation DC Resistance at 20°C ($\text{M}\Omega \cdot \text{KM}$) :

>500

Current Rating : 16 A

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$

Insulation: PVC

Insulation Dia. (mm): $2.8 \pm 0.1 \times 7\text{C}$

Filler: Chalk

Jacket: PVC

Outer Dia. (mm): 10.2 ± 0.25

Colour:

The color of the insulation: Black x 6 ,
Yellow/Green

The jacket color: Grey (RAL-7001)

Marking(3times/m):

RS 522484 YY/NR 7 Core x 1.5mm²

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300