


**PRKT...**

**MICRO (M12) Single-Ended Cordset**  
 4 and 5 Pole, Female, Straight, PVC Cable with Stainless Steel Coupling Nut

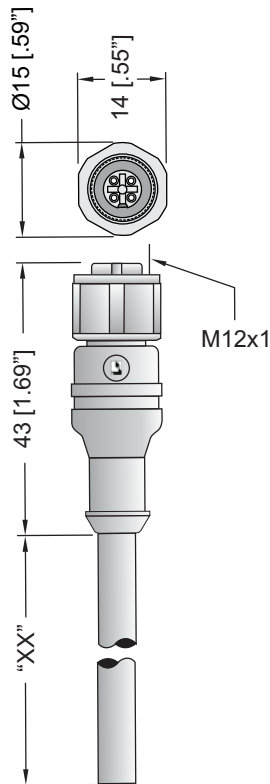

**Technical Data**

**Material**

Molded Body	PVC, Orange
Coupling Nut	Stainless Steel
Contacts	Brass, gold over nickel plated
Insert	PVC, Orange
O-Ring	EPDM

**Electrical**

Current Rating	4A
Voltage Rating	
4 Pole	250 V
5 Pole	32 VAC/VDC

**Mechanical**

Temperature	-25°C to +70°C
Protection	IP 69 K

**Cable Specifications**

Cable Jacket	PVC, Orange
Overall Diameter	
4 Pole	5.0mm
5 Pole	5.7mm
Conductor	
4 Pole	0.25mm <sup>2</sup> , stranded
5 Pole	0.34mm <sup>2</sup> , stranded


**Certifications**




**Features & Benefits**

- 316LV4A stainless steel coupling nut
- PVC inserts, molded body and cable jacket
- EPDM O-ring seal
- IP 69 K rated

**Pin Assignments**

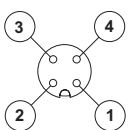

- 1 - Brown
- 2 - White
- 3 - Blue
- 4 - Black

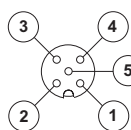

- 1 - Brown
- 2 - White
- 3 - Blue
- 4 - Black
- 5 - Gray

**Part Number**

**Poles**

PRKT 4-07/5M	
PRKT 4-07/10M	4
PRKT 4-07/25M	
PRKT 5-56/5M	
PRKT 5-56/10M	5
PRKT 5-56/25M	