


**71600-020LF - Quickie® : Receptacle -  
Double row - 20 Positions - 2.54 mm (0.1  
in.)**

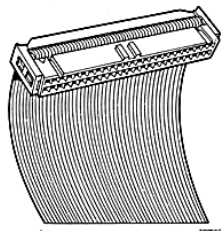

[www.fci.com](http://www.fci.com)

## Mating Half

71918-120LF

71922-120LF

## Specifications

### General

<b>Insulation Displacement Contact (IDC)</b>	IDC Receptacle
<b>Number of contacts (Total)</b>	20
<b>Number of rows</b>	2
<b>Polarization</b>	Center and Dual
<b>Strain Relief</b>	Standard
<b>Style</b>	Standard Single Beam
<b>Termination Style</b>	IDC
<b>Application Equipment</b>	QP-104 QP-112 QP-106
<b>Mating half</b>	Mates with shrouded Eject Latch Header Latch 1

### Electrical

<b>Current rating</b>	1 amp Continuous
<b>Resistance (Contact)</b>	15 m ohms max.
<b>Resistance (Insulation)</b>	50000 M-ohms
<b>Voltage rating</b>	1000V AC rms

### Physical

<b>Color (Housing)</b>	Grey
<b>Material (Contact)</b>	Phosphor Bronze
<b>Material (Housing)</b>	Glass - Filled Thermoplastic Polyester
<b>Plating (Contact area)</b>	0.76 µm (30 µin.) Gold
<b>Underplating (Contact)</b>	1.27 µm (50 µin.) Nickel
<b>Flammability rating</b>	UL 94 V-0
<b>Temperature (Range)</b>	-65°C to +105°C

### Approvals / Certifications

<b>UL File Number</b>	E66906
<b>CSA File Number</b>	LR46923
<b>Approvals / Certifications</b>	UL and CSA Approved

### Other Features

<b>Packaging (Type)</b>	Tube
-------------------------	------