

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51015-0400](#)
Status: **Active**
Description: 2.00mm Pitch Board-in Crimp Housing, Low Profile, 4 Circuits

Documents:

3D Model	Product Specification PS-51015-002 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-51015-001 (PDF)	

General

Product Family	Crimp Housings
Series	51015
Application	Signal
Product Name	Board-In
UPC	800753575752

Physical

Circuits (maximum)	4
Color - Resin	Natural
Gender	Male
Glow-Wire Compliant	No
Material - Resin	Nylon
Net Weight	78.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Reference - Drawing Numbers

Product Specification	PS-51015-001, PS-51015-002, RPS-51015-001, RPS-51015-003, RPS-51015-004, RPS-51015-006
Sales Drawing	SD-51015-**00

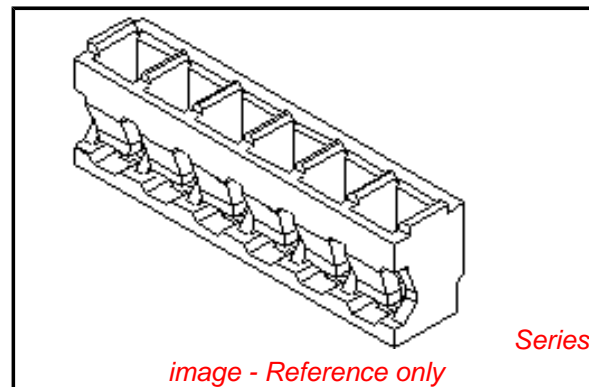


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Not Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

51015Series

Use With

50034

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION