

Panel mounting base - RC-0000000E000 - 1592813


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Panel mounting base, straight, Screw locking, M23, Radial O-ring, 4xM3, Shielded: Yes, Panel thickness min.: 3 mm, Panel thickness max.: 10.5 mm, Cable diameter: 0 mm...0 mm



Key commercial data

Packing unit	40 pc
GTIN	 4 046356 192897
Weight per Piece (excluding packing)	37.78 g
Custom tariff number	85366990
Country of origin	Germany

Technical data

General

Note	Order information Order contact inserts separately
Type of locking	Screw locking
Contact connection method	Crimp connection
Type of contacts	Socket
Conductor entry	0 mm ... 0 mm
Mounting type	4xM3

Ambient conditions

Ambient temperature	-20 °C ... 125 °C
Degree of protection	IP67

Material

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Gasket and O-ring material	FPM

Specifications according to DIN EN 61984:2001

Installation height max.	2000 m
--------------------------	--------

Panel mounting base - RC-0000000E000 - 1592813

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260708
eCl@ss 7.0	27440312
eCl@ss 8.0	27440312

ETIM


ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC000437

UNSPSC


UNSPSC 6.01	43172015
UNSPSC 7.0901	43201404
UNSPSC 11	43172015
UNSPSC 12.01	43201404
UNSPSC 13.2	43201404

Drawings


Diagram

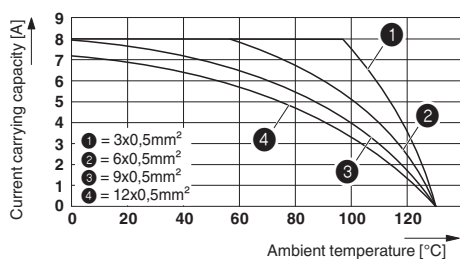


Diagram

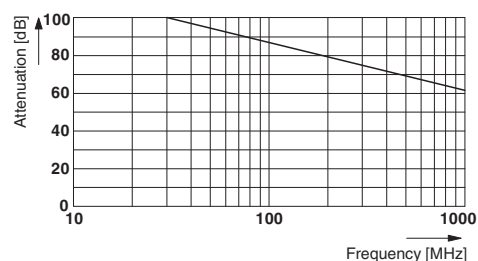

Dimensioned drawing

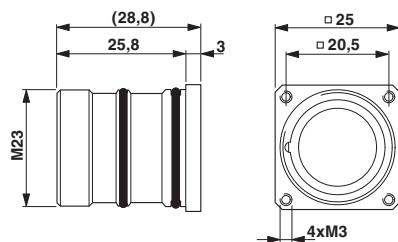

Dimensioned drawing

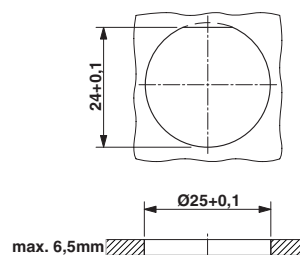

Panel mounting base - RC-0000000E000 - 1592813

Dimensioned drawing

