

## Datasheet

# DPDT Socket Mount Non-Latching Relay, 10 A, 230V ac

RS Stock number [348-762](#)




## Description:

10A Industrial Relay


- Protected by a clear polycarbonate cover
- DIN Rail or Surface Mounting
- Contact Rating is 10A
- Maximum switching voltage 250 Vac, 30 V dc
- Mechanical Life of  $10^7$  Operations (min)
- Electrical Life of  $10^5$  Operations (min)
- Maximum temperature at rated coil voltage 65°C
- Sockets available (8 pin stock no. [403-235 & 402-147](#), 11 pin stock no. [402-153 & 403-241](#))
- Relay Cover available for 11 pin relay [402-169](#)

## Specifications:

Application:	Power
Coil Power:	2VA
Coil Resistance:	8200 $\Omega$
Coil Voltage:	230V ac
Contact Configuration:	DPDT
Contact Material:	Silver Cadmium Oxide
Depth:	35mm
Height:	56mm
Isolation Coil To Contact:	1500V ac
Length:	35mm
Maximum Operating Temperature:	+55°C
Maximum Switching Current:	AC 10 A
Maximum Switching Current:	DC 10 A
Maximum Switching Voltage:	AC 240V
Maximum Switching Voltage:	DC 30V
Minimum Operating Temperature:	-45°C
Mounting Type:	Socket Mount
Terminal Type:	Through Hole
Weight (approx.):	88g
Contact resistance:	50m $\Omega$ Maximum

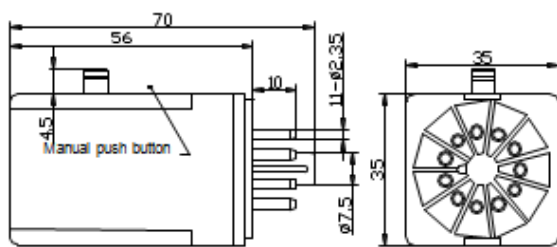

**3C**

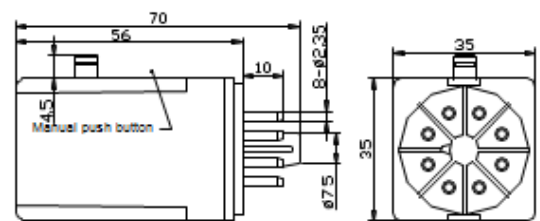

**1C or 2C**