


LSCS shaft blocks

d_a 8-80 mm

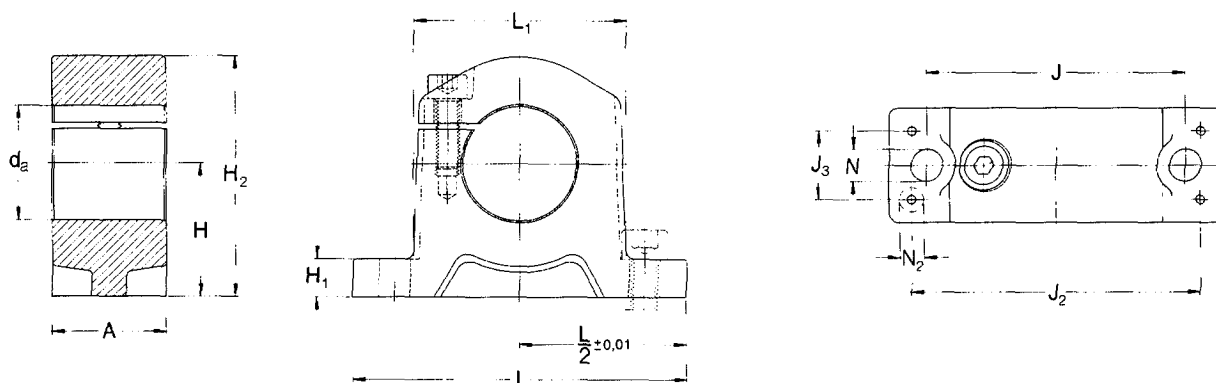

| Dimensions | | | | | | | | | | | Mass | Designations | |
|------------|----|----|-------|-------|-----|-------|-------|-----|-------|----------|-------|--------------|----------------|
| d_a | A | H | H_1 | H_2 | J | J_2 | J_3 | L | L_1 | $N^{1)}$ | N_2 | | Shaft block |
| mm | | | | | | | | | | | kg | — | |
| 8 | 10 | 15 | 5,5 | 25 | 25 | 35 | 5 | 45 | 19 | 4,3 | 2,7 | 0,012 | LSCS 8 |
| 12 | 12 | 20 | 6 | 32,5 | 32 | 42 | 6 | 52 | 25 | 5,3 | 3,2 | 0,023 | LSCS 12 |
| 16 | 15 | 20 | 7 | 35,5 | 40 | 46 | 7,5 | 56 | 31,8 | 5,3 | 4,3 | 0,034 | LSCS 16 |
| 20 | 20 | 25 | 8 | 43,5 | 45 | 58 | 10 | 70 | 37 | 5,3 | 5,3 | 0,065 | LSCS 20 |
| 25 | 28 | 30 | 10 | 53 | 60 | 68 | 16 | 80 | 48 | 6,4 | 6,4 | 0,14 | LSCS 25 |
| 30 | 30 | 35 | 10 | 63 | 68 | 76 | 18 | 88 | 56 | 8,4 | 6,4 | 0,20 | LSCS 30 |
| 40 | 36 | 45 | 12 | 81 | 86 | 94 | 22 | 108 | 71 | 10,5 | 8,4 | 0,47 | LSCS 40 |
| 50 | 49 | 50 | 14 | 92,5 | 108 | 116 | 30 | 135 | 86 | 10,5 | 10,5 | 0,68 | LSCS 50 |
| 60 | 62 | 60 | 18 | 112 | 132 | 138 | 40 | 160 | 105 | 13 | 13 | 1,29 | LSCS 60 |
| 80 | 85 | 80 | 22 | 147,5 | 170 | 180 | 60 | 205 | 136 | 17 | 15 | 3,01 | LSCS 80 |

¹⁾ For screws with internal hexagon to DIN 912 / ISO 4762.