

## Datasheet


### RS M32 Black Nylon Cable Gland With Locknut, 18 → 25mm Cable Dia Range, IP68

RS Stock number 669-4670



|                               |          |
|-------------------------------|----------|
| Colour                        | Black    |
| IP Rating                     | IP68     |
| Locknut Included              | Yes      |
| Material                      | Nylon 66 |
| Maximum Cable Diameter        | 25mm     |
| Maximum Operating Temperature | +85°C    |
| Minimum Cable Diameter        | 18mm     |
| Minimum Operating Temperature | -60°C    |
| Thread Size                   | M32      |

LOCK NUT

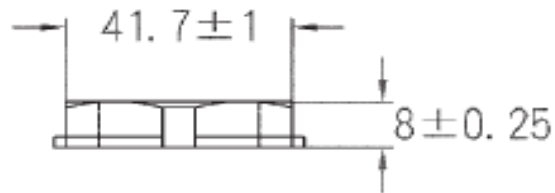


WASHER

External thread  
M32x1.5

BODY

CLAW

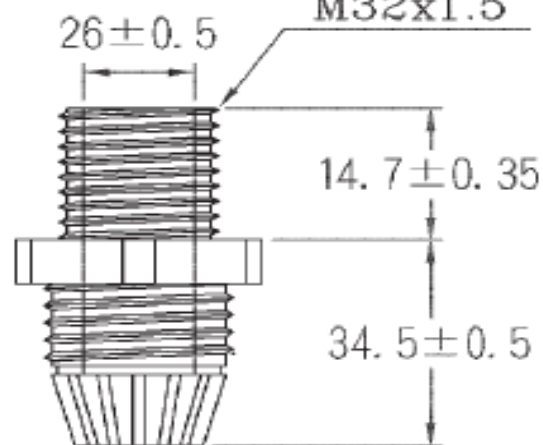

SEALS



NUT

