
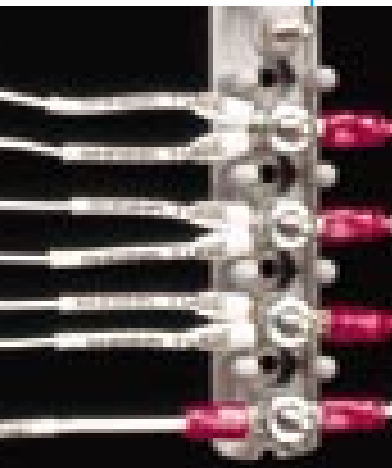


Identify with
KROY®

K3100PC

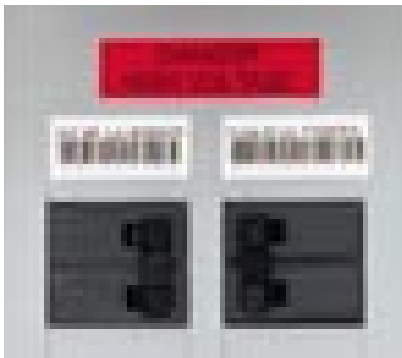


The companion printer to the portable Kroy K2500, the K3100PC is a versatile desktop printer with 300dpi resolution. With its very small footprint and compact design, the K3100PC fits comfortably alongside your PC and allows you to print a variety of labels on demand, when ever you need them.

The K3100PC comes complete with Windows drivers, cable, mains adaptor and the powerful Kroy Label Design Software (KLDS). The unique easy loading supply cartridge offers the flexibility of printing shrink tubing, self laminating wire markers, die-cut labels and continuous polyester or cast vinyl labels direct from your PC.

The KLDS software with its resident barcode library (including 2D barcodes), drawing and text tools, makes label printing with the Kroy K3100PC as easy as a few clicks on your mouse.

KROY®

K3100PC

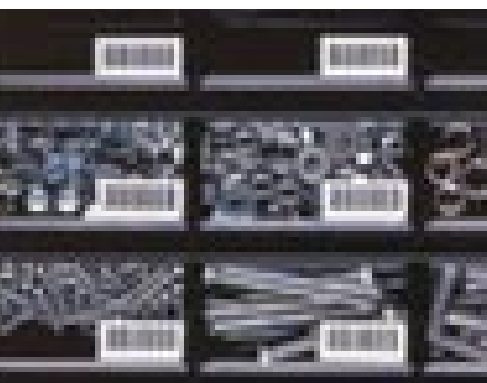

Printing

- Thermal transfer and direct thermal printing
- Resolution: 12 dots per mm 300dpi
- Max. print width: 24.7mm (0.97")
- Max. label width: 25.4mm (1")
- Max. print length: 508mm (20")
- Maximum 50mm per second (2")

Dimensions

- Printer: 152mm L (6") x 95mm W (3.75") x 101mm H (4")
- Electrical specifications and approvals:
AC adaptor supplied
Output 14 VDC, 1.6Amp - UL listed, CSA
Certified, TUV "GS" approval and CE
Meets VDE-B and FCC part 15 class B RFI limits

Media specifications

- Widths: 12.7mm (0.5"), 20mm (0.8"), 25.4mm (1")
- Length: 12m (40')
- Shrink tube length: 2.8m (110")
- Easy loading self contained cartridges
- Laminated and non laminated polyester, cast vinyls, self laminating labels, "Void" polyester, destructible polyurethane, polyolefin shrink tubing, direct thermal papers and synthetic paper die-cut labels

Environmental

- Operating temperature: 45°F to 105°F (7°C to 40°C)
- Supply cartridge storage temperature: 60°F to 105°F (15°C to 40°C) shelf life is reduced at higher temperatures - damage may occur at temperatures as high as 120°F (50°C)
- Operating/storage humidity limit: 90% RH non-condensing



Accessories included:

- Windows drivers: Windows 95, 98 and NT 4.0
- Kroy Label Design Software (KLDS)
- Mains adaptor
- Interface cable

Tape supplies

12.7mm width

	Polyester part no	Vinyl part no
Black on clear:	2558501	2558301
White on clear:	2558502	n/a
Black on white:	2558516	2558316
Blue on white:	2558517	n/a
Black on silver:	2558521	2558321
Black on blue:	2558531	2558331
Black on red:	2558535	2558335
Black on green:	2558539	2558339
Black on yellow:	2558543	2558343
Black on orange:	2558548	2558348

25.4mm width

	Polyester part no	Vinyl part no
Black on clear:	2438001	2558101
White on clear:	2438002	n/a
Black on white:	2438016	2558116
Blue on white:	2438017	n/a
Black on silver:	2438021	2558121
Black on blue:	2438031	2558131
Black on red:	2438035	2558135
Black on green:	2438039	2558139
Black on yellow:	2438043	2558143
Black on orange:	2438048	2558148

Tube supplies

	Black on white:	Black on yellow:
3.2mm (1/8")	2470001	2470002
4.8mm (3/16")	2470011	2470012
6.4mm (1/4")	2470021	2470022
9.6mm (3/8")	2470031	2470032
12.7mm (1/2")	2470041	2470042

KROY®

Kroy (Europe) Limited
Unit 2, 14 Commercial Way
Reading, Berkshire, RG2 0QJ England
Tel +44 (0)118 9865 200 Fax +44 (0)118 9865 205
www.Kroy.com

©1994 Kroy (Europe) Ltd. Kroy and DuraType are registered trademarks of Kroy Inc. Subject to product availability.
Specifications and pricing may change at any time without notice.

France
Service Commercial Tel +33 1 48 69 58 18
Germany
Kundendienst Tel +49 2464 907142



Part Number LTK3000PCUK