

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [172159-0611](#)
Status: **Active**
Overview: EdgeMate™ Wire-to-Edge-Card Power Connector
Description: 3.96mm Pitch EdgeMate Crimp Housing, Female, Nylon 6/6, White, UL94-V2, with Positive Lock, 11 Circuits

Documents:

[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-172160-0001 \(PDF\)](#)
[Packaging Specification PK-172159-0001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
Series [172159](#)
Application Power, Wire-to-Edge Card
Comments Current = 7A max. per circu...
Overview EdgeMate™ Wire-to-Edge-Card Power Connector
Product Name EdgeMate™
UPC 887191569987

Physical

Circuits (maximum) 11
Color - Resin White
Gender Female
Glow-Wire Compliant No
Lock to Mating Part Yes
Material - Resin Nylon
Net Weight 4.100/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.96mm
Pitch - Termination Interface 3.96mm
Polarized to Mating Part Polarizing Ribs
Stackable No
Temperature Range - Operating 0°C to +75°C


Electrical

Current - Maximum per Contact 7A

Material Info

Reference - Drawing Numbers

[Packaging Specification](#) PK-172159-0001
[Product Specification](#) PS-172160-0001
[Sales Drawing](#) SD-172159-0002

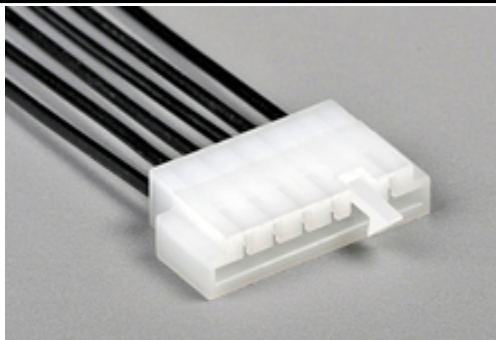

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[172159Series](#)

Mates With

Edge Card PCB

Use With

[172160](#)