


**Weller**

**.031" x 0.62" x 700° PT Series Conical Tip for TC201 Series Iron**

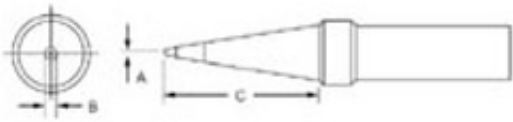

◀◀ previous print close next ▶▶

**Product Details**

|                                  |  |
|----------------------------------|--|
| <b>Catalog No.</b>               | <b>PTP7B</b>   |
| <b>UPC Code</b>                  | <b>037103477729</b>                                      |
| <b>Fits Tool(s)</b>              | <b>TC201T</b>  |
| <b>Tip Style</b>                 | <b>Conical</b>   |
| <b>Tip Width O/D</b>             | <b>.031 in./ .79 mm</b>                                  |
| <b>Tip Thickness/Height/ I/D</b> | <b>.012 in./ .30 mm</b>                                  |
| <b>Reach/Length</b>              | <b>.62 in./ 15.75 mm</b>                                 |
| <b>Packaging</b>                 | <b>Peg Hook/Retail Packaging</b>                         |
| <b>Tech. Spec.</b>               | <b><u><a href="#">Solder Safety Warnings.pdf</a></u></b> |
| <b>Lineart</b>                   | <b><u><a href="#">PT Conical.pdf</a></u></b>             |
| <b>Low Res. Image</b>            | <b><u><a href="#">PT Conical 100.jpg</a></u></b>         |
| <b>High Res. Image</b>           | <b><u><a href="#">PT Conical 300.jpg</a></u></b>         |
| <b>Stock Item</b>                | <b>Normal Stock Item</b>                                 |

**Package Details (Dimensions)**

Email this Page

**Product Features:**

- **Solid copper, plated with iron all over**
- **Nickel and chromium behind the working surface**
- **Designed to provide maximum heat transfer from the heater to the tip**
- **Individually bagged**