
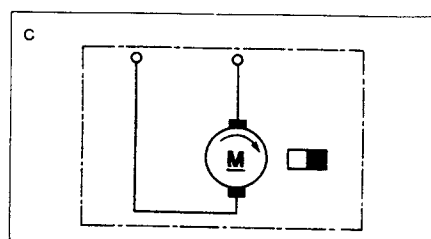


CPB

RS stock no: 226-1099

12 V 75 W

Nominal voltage	U_N	12 V
Nominal output	P_N	75 W
Nominal current	I_N	12 A
Nominal speed	n_N	4800 min ⁻¹
Continuous torque	M_D	15 N · cm
Tightening torque	M_A	105 N · cm
Direction of rotation		R
Type of duty		S1
Degree of protection		IP 10
Weight		0.71 kg
Diagram		c
Part number		0 130 063 004

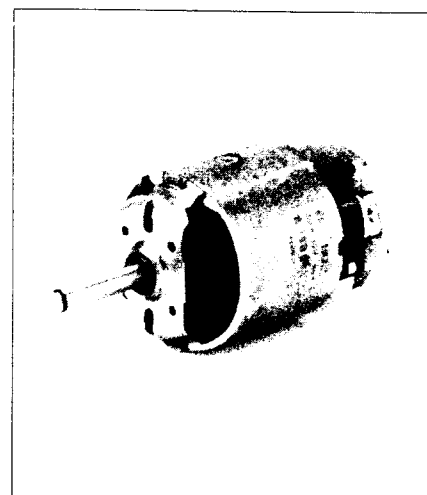

CPB (continued)

RS stock no: 226-1106

24 V 72 W

Nominal voltage	U_N	24 V
Nominal output	P_N	72 W
Nominal current	I_N	4 A
Nominal speed	n_N	4600 min ⁻¹
Continuous torque	M_D	15 N · cm
Tightening torque	M_A	104 N · cm
Direction of rotation		LR
Type of duty		S1
Degree of protection		IP 10
Weight		0.73 kg
Diagram		e
Part number		0 130 063 090

