

Rhino**PRO** 3000TM **HARD CASE KIT**

One Easy Package for Fast, Professional Labelling!

The **RhinoPRO 3000 Hard Case Kit** combines a rugged carry case with the industry's best portable label printer – the RhinoPRO 3000. Featuring all you need to get up and running quickly – including labels and batteries – and a case to protect your printer in industrial or other harsh environments, you now get all the affordable and convenient features of the RhinoPRO 3000 in one handy and strong package.

RhinoPRO 3000 Features and Benefits:

- Simple one-touch Hot Keys for cable/wire wraps, wire/cable flags, fixed length and vertical printing, and distribution panels
- 150 Pre-Programmed Hot Keys
 - Room Locations
 - Audio/Video components
 - Voice/Data components
 - Security
- Impact-resistant rubber bumper provides extra protection
- Auto shut-off to eliminate running out of power on the job
- 25 memory locations
- Serialized printing for text & numbers
- Easy-to-load “all-in-one” RhinoPRO label cassettes
- Easy-to-peel RhinoPRO labels available in 6 mm, 9 mm, 12 mm.
- Holds up to 10 tapes, plus room for tools



Convenient Package Includes:

- Durable hard carry case
- RhinoPRO 3000 printer with impact-resistant bumper
- One 12 mm white Permanent Polyester label cassette
- One 12 mm white Flexible Nylon label cassette
- AC power adapter
- 6 “AA” batteries
- Quick Start Guide and User Manual

RHINO TM
PROFESSIONAL LABELLING TOOLS
HOW DO YOU SIGN YOUR WORK?

RhinoPRO 3000 HARD CASE KIT

Making Your Installation Look More Professional.

RhinoPRO Labels:


- Thermal transfer print technology is durable, smearproof, and resists chemicals, solvents, grease, heat, moisture and other harsh elements.
- Permanent adhesive results in labels that stick and last in harsh industrial environments.
- Easy-to-peel split-back labels.



Easy-peel split-back label

Labelling with "Hot Keys":

- Cable/Wire Wrapping
- Flagging
- Fixed Length labels
- Vertical labels
- And many more...

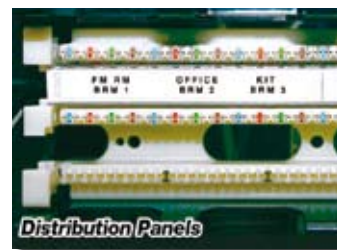

- Powerful text Hot Keys give you the ability to choose from over 150 common locations and items around the home and job site – saving you valuable time. Here's a sample of the many choices...

Location:	Den Family Room Master Bedroom Billiards Room Garage Kitchen Basement	Audio/Video:	CATV Center Back Speaker DVD/ VCR Left Surround Speaker Subwoofer S-Video	Security:	Back Door Camera CCTV Driveway Motion Sensor Smoke detector	Voice/Data:	Cable Modem Demarc Fax Phone
<i>And, many, many more...</i>							

- LABEL SELECTION CHART -

Surface applications	Material	6 mm	9 mm	12 mm	Lenght
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Indoor Surfaces	White Flexible Nylon	n/a	n/a	18758	3,5 m
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Indoor Surfaces	Yellow Flexible Nylon	n/a	n/a	18756	3,5 m
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Surfaces	Yellow Vinyl	n/a	18431	18432	5,5 m
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Outdoor Surfaces	Orange Vinyl	n/a	18434	18435	5,5 m
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Outdoor Surfaces	Red Vinyl	n/a	18437	18438	5,5 m
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Surfaces	Green Vinyl	n/a	18440	18441	5,5 m
Wire/Cable/Curved/Smooth/Flat/ Textured/Highly Textured Surfaces	White Vinyl	n/a	18443	18444	5,5 m
Smooth/Flat/Textured Surfaces	White Permanent Polyester	n/a	18766	18764	5,5 m
Smooth/Flat/Textured Surfaces	Metallized Permanent Polyester	n/a	18760	18761	5,5 m
Smooth/Flat/Textured Surfaces	Clear Permanent Polyester	n/a	18508	n/a	7 m
Wire and Cable	White Heat Shrink Tube	18051	18053	18055	1,5 m
Wire and Cable	Yellow Heat Shrink Tube	18052	18054	18056	1,5 m
Insert	White Non-Adhesive Tag	18111	18112	18113	5,5 m
Insert	Yellow Non-Adhesive Tag	18115	18116	18117	5,5 m

Product Specifications:

- Codenummer : 19895
- RhinoPRO 3000
 - Dimensions : 114 mm H x 53 mm W x 190 mm L
 - Weight: 363 gr



DYMO bvba
Industriepark-Noord 30
B-9100 Sint-Niklaas
Belgium



For more information or to find your nearest RhinoPRO distributor, please visit www.dymo.com or call us at (+44) 020 7341 5529