




Price\* : 12.30 GBP

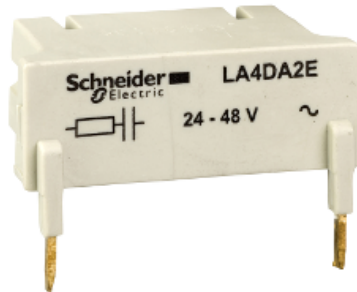

## Main

Range	TeSys
Device short name	LA4D
Product or component type	Suppressor module
Product compatibility	LC1D40008...D80008 (4P) LC1D80...D95 (3P) LC1D80004 (4P)

## Complementary

Mounting location	Top
Mounting mode	By screws
Suppressor technology	Bidirectional peak limiting diode
[Uc] control circuit voltage	24 V DC
Maximum peak voltage	2 Uc
Product weight	0.018 kg

## Environment

Ambient air temperature for operation	-25...55 °C
Ambient air temperature for storage	-40...80 °C

## Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0805 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold <a href="#">Reference not containing SVHC above the threshold</a>
Product environmental profile	Available

---

Product end of life instructions	Need no specific recycling operations
----------------------------------	---------------------------------------

---

**Contractual warranty**

---

Warranty period	18 months
-----------------	-----------

---