



# Control Panel Trunking

## Betaduct PVC Open Slot Black

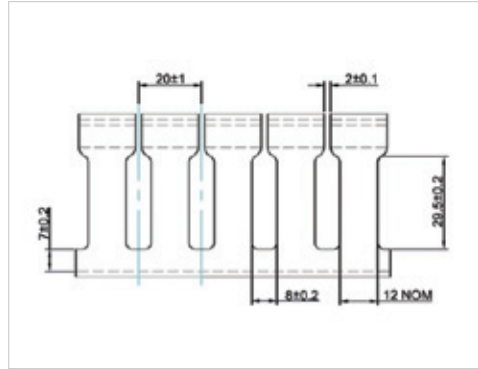

B

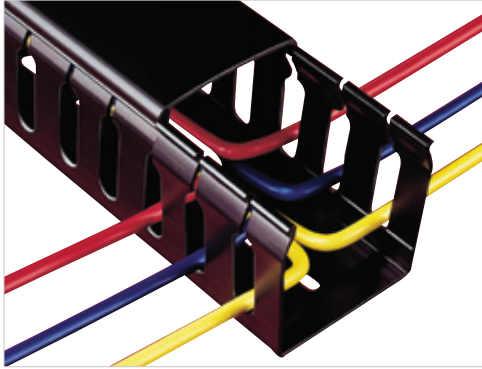

Open Slot PVC Betaduct provides a lightweight self-extinguishing cable trunking with excellent rigidity and performance characteristics. Wide fingers give additional cable support and terminated wires can be re-routed easily. Ideal for use when bundles, cables and wires need supporting in control panels, distribution boards and switchgear. Ideal for all panel building applications.

Available in 23 sizes. Recommended fixing method; Betaduct rivets or washers. Supplied with lid.

### SPECIFICATIONS

**MATERIAL:**

Self-Extinguishing PVC

**SLOT PITCH:** 20mm **SLOT WIDTH:** 8mm **WEBS:** 12mm

**COLOUR:**

Black RAL 9005

**SERVICE TEMPERATURE RATING:**

-15°C to +60°C

**FLAMMABILITY:**

UL94 V-0 Rated Material

**STANDARDS:**

Base slots to DIN 43659. RoHS, CSA, UL and Lloyds Register Approved.

PART NO. BLACK	NOMINAL SIZE INNER (WxH) mm	NOMINAL SIZE OUTER (WxH) mm	PACK QTY (m)
0980	19 x 50	25 x 53	24
0981	25 x 37.5	29 x 41	24
0913	25 x 50	29 x 54	24
0914	25 x 75	29 x 79	16
0983	25 x 100	30 x 105	16
0984	37.5 x 37.5	41 x 41	24
0985	37.5 x 50	41 x 54	16
0986	37.5 x 75	39 x 79	16
0987	37.5 x 100	43 x 105	16
0988	50 x 25	54 x 28	24
0989	50 x 37.5	54 x 41	16
0916	50 x 50	54 x 54	16
0917	50 x 75	55 x 79	16
0992	50 x 100	56 x 105	8
0993	75 x 37.5	80 x 41	16
0994	75 x 50	78 x 54	16
0919	75 x 75	80 x 80	16
0996	75 x 100	80 x 105	8
0998	100 x 50	107 x 54	8
0999	100 x 75	107 x 80	8
1000	100 x 100	107 x 107	8
1001	100 x 125	107 x 130	8
0941	125 x 75	131 x 78	8

