


TT3 20-4-4

Isolating transformer

- Safety electrical isolation
- $\pm 5\%$ secondary tapings for easy adaption of the voltage
- Screw mounting

Isolating transformer to IEC 61558-2-4, DIN EN 61558-2-4,
VDE 0570 part 2-4

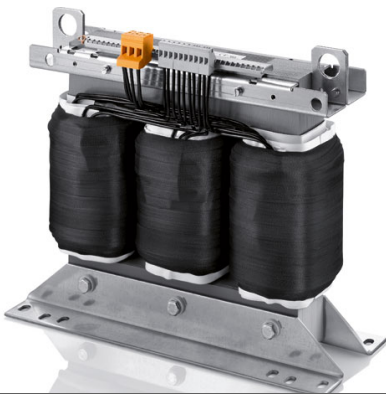

TT3 20-4-4

Isolating transformer



Input data	
Rated voltage	3 x 400 V
Short circuit voltage	≤3 %
Rated current	3 x 29,4 Aac
Frequency range	50 - 60 Hz
Output data	
Rated voltage	3 x 380 V; 3 x 400 V; 3 x 420 V
Rated current	3 x 30,4 Aac (3 x 380 V); 3 x 28,9 Aac (3 x 400 V); 3 x 27,5 Aac (3 x 420 V)
Power	20000 VA
Standards and security	
Protection index	IP 00
Safety class (prepared)	I
Ambient temperature max.	50 °C
Class of Insulation System	F
Test voltage	4800 V
General data	
Vector group	Dyn 5
Power loss	525.0 W
Mechanical data	
Type	open type
Core type	3UI 240/140
Terminals	screw type terminals
Fixing method	mounting brackets
Fixing screws	-
Dimensions W x H x D	550 x 510 x 297
Weight	180.00 kg

BLOCK Transformatoren-Elektronik GmbH

Max-Planck-Straße 36-46

27283 Verden

Germany

Phone +49 4231 678-0

Fax +49 4231 678-177