




ENGLISH

Product Datasheet


Screw Disconnect Terminal Blocks, 4sq.mm

Screw Clamp Disconnect Terminal Blocks, 22A, 600V, 22-10 AWG, 0.5-4 sq.mm

878-7588

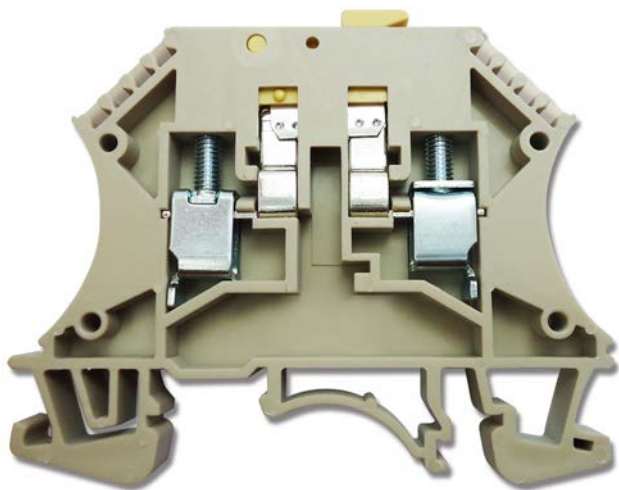


 

 
 

Dimensions in mm

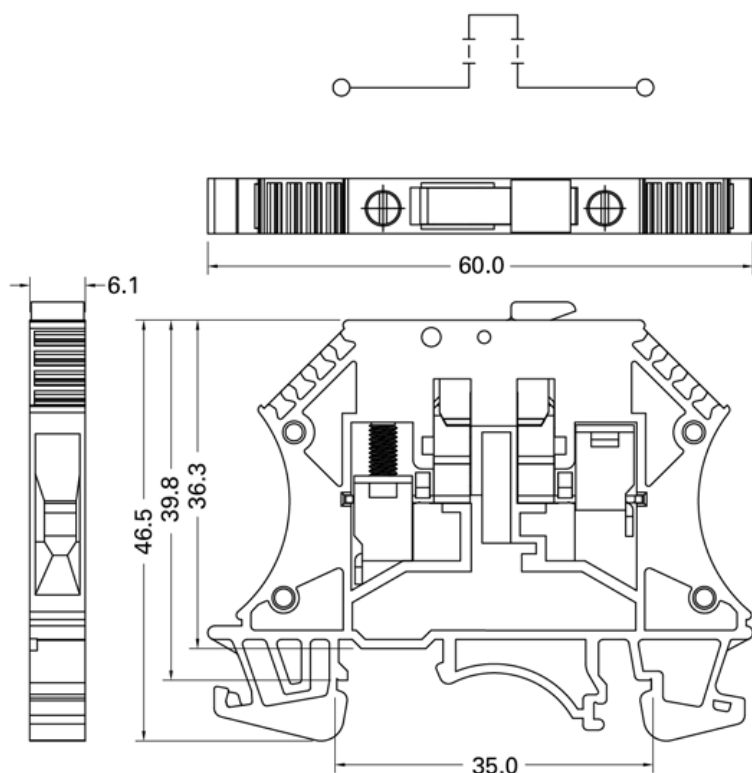

RoHS
Compliant



Product Specifications:

Specifications	4mm ²
Technical Date	Rated voltage / Rated current / Wire size
UL	600V / 22A / AWG 22-10
CSA	600V / 22A / AWG 22-10
IEC	500V / 22A / 0.5-4mm ²
Insulating impulse voltage withstand/pollution degree	6KV / 3
Torque (in -lbs)	6
Clamping Screw (M)	M3
Insulation stripping length (mm)	10~12 mm
Net weight per piece	10.7 g
Material / Available Color (Standard Color: Beige)	 Red Orange Beige Blue Grey White Black
Rail Dimensions	T / W / H (mm)
For TS35x7.5 	6.1 x 60 x 47.5
For TS35x15 	6.1 x 60 x 55
Accessories	Cat. No.
End Bracket 	8787553
	8787556
End plate 	8787540