




ENGLISH

## Datasheet

Stock No: 522-636

# RS Pro 4 Core Screened CY Control Cable, Polyvinyl Chloride PVC Sheath

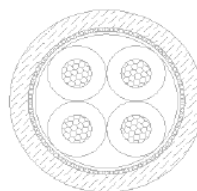

### Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V):300

### Construction:

Conductor: Bare Copper

Conductor Dia. (mm): 0.25±0.008 x 50

Insulation: PVC

Insulation Dia. (mm): 3.4±0.1 x 4C

Tape Mylar: ≥115%

Braid Shield : Tinned Copper

Conductor Dia. (mm): 0.16

Conductor Qty: 16 x 8

Pitch(mm):

Coverage: 70%

Jacket: PVC

Outer Dia. (mm):10.7±0.2

### Colour:

The color of the insulation: Grey , Brown , Black , Yellow/Green

The jacket color: Grey (RAL-7001)

### Marking(3times/m):

RS 522636 CY/CC 4 Core x 2.5mm<sup>2</sup>

### Performance:

#### Electrical Characteristics:

Max.Conductor DC Resistance at 20°C ( Ω/Km) : <8.2

Min.Insulation DC Resistance at 20°C (MΩ\*KM) : >500

Current Rating : 20 A