

**Ordering number C11816**
Description 1

Family	Strada-SQ	FWHM	Asym degrees
Type	Lens	Efficiency	(simulated) 0 %
LED	Z5	cd/Im	-
Color	Clear	Gerber File	Available
Diameter	25 + 25 mm		
Height	8.77 mm		
Style	Square		
Optic Material	PMMA		
Holder Material	-		
Fastening	-		
Status	Ready		

Ordering number CA11817
Description 1


Family	Strada-SQ	FWHM	Asym degrees
Type	Assembly	Efficiency	(simulated) 0 %
LED	Z5	cd/Im	-
Color	Clear	Gerber File	Available
Diameter	25 + 25 mm		
Height	8.92 mm		
Style	Square		
Optic Material	PMMA		
Holder Material	-		
Fastening	-		
Status	Ready		



PRODUCT DATASHEET
Strada-SQ series
last update 8/3/2013



NOTE: The typical divergence will be changed by different color, chip size and chip position tolerance. The typical total divergence is the full angle measured where the luminous intensity is half of the peak value.

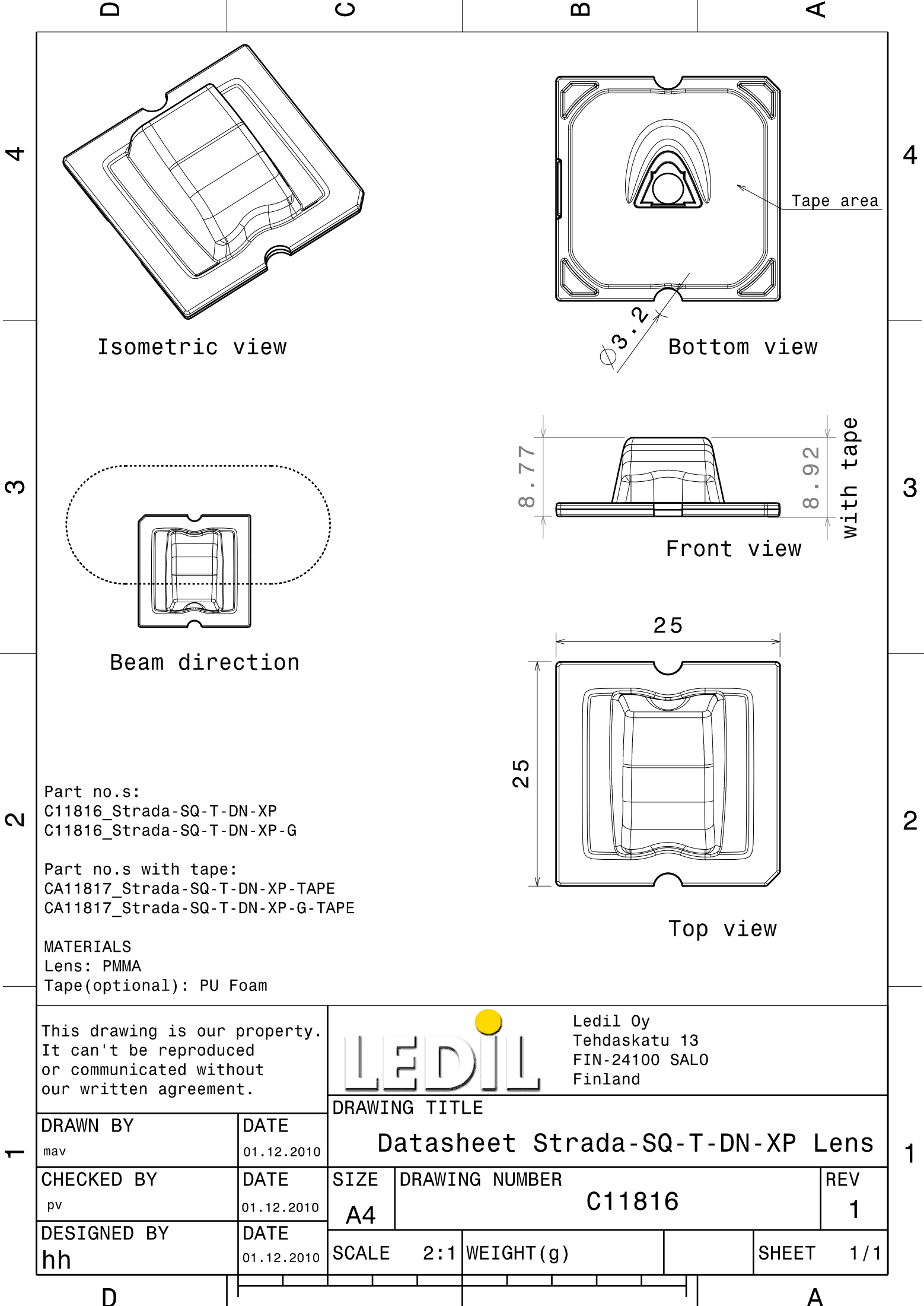

Part no.s:
C11816_Strada-SQ-T-DN-XP
C11816_Strada-SQ-T-DN-XP-G

Part no.s with tape:
CA11817_Strada-SQ-T-DN-XP-TAPE
CA11817_Strada-SQ-T-DN-XP-G-TAPE

MATERIALS
Lens: PMMA
Tape(optional): PU Foam

This drawing is our property. It can't be reproduced or communicated without our written agreement.		 Ledil Oy Tehdaskatu 13 FIN-24100 SALO Finland	
		DRAWING TITLE	
DRAWN BY	DATE	Datasheet Strada-SQ-T-DN-XP Lens	
mav	01.12.2010		
CHECKED BY	DATE	SIZE	DRAWING NUMBER
pv	01.12.2010	A4	C11816
DESIGNED BY	DATE	SCALE	WEIGHT (g)
hh	01.12.2010	2 : 1	
			SHEET 1 / 1