




HAKKO FX-9501

● HAKKO FX-9501 soldering iron

Power consumption	70 W (24V)
Tip to ground resistance	< 2 Ω
Tip to ground potential	< 2 mV
Length of cord	1.2 m (4 ft.)
Length, (w/o cord)	202 mm (7.95 in.) with 2.4D tip
Weight, (w/o cord)	40 g (0.09 lb.) with 2.4D tip

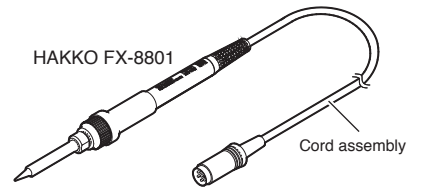

HAKKO FX-8801

Cord assembly

● HAKKO FX-8801 Soldering iron

Power consumption	AC26V 65W
Tip to ground resistance	< 2 Ω
Tip to ground potential	< 2 mV
Heating element	Ceramic heater
Cord	1.2m (3.9 ft.)
Total length (w/o cord)	217mm (8.5 in.) with B tip
Weight (w/o cord)	46g (0.10 lb. / 1.62 oz.) with B tip



∅4.4 (I.D)

A1130 Single

Size 4.4

Vacuum function inoperative nozzle



Model No.809

Type Gun

Power consumption AC 24V/50W

Temperature range 380 – 480oC



599B

Wire-type soldering iron tip cleaner best suited for lead-free soldering

Features

Specialized for cleaning tips used for lead-free solder

No water required for cleaning, minimizes the drop in tip temperature at each cleaning to ensure better workability.

Dome-shaped design reduces solder splash

Flux contained in cleaning wires prevents oxidation of soldering tips