



All 3M Products Innovation Explore 3M

Search



United States  [Change](#)


Electrical Commercial and Industrial

[Products](#) | [Documentation & Literature](#) | [News & Tradeshow](#) | [Support](#) |

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) > _____

3M™ Highland™ Vinyl Insulated Female Disconnect Terminal FDV14-187Q, AWG 16-14, 25/bag

3M ID 80611602667 UPC# 00051128600054 3M Product Number FDV14-187Q

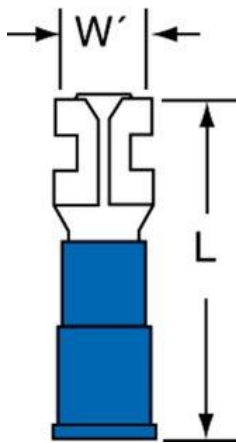

This female disconnect accepts a wire range of 16-14 AWG, a stud size of .187 and has a case quantity of 10 bags.

Overview

Documentation

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.085 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	16 - 14 AWG
CSA File Number	LR22190
Fastener Orientation	Female
Insulation Material	Vinyl
Length (L)	0.78 Inch
Mates with Male Tab Width (W')	0.187 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	25 per bag
Pad Width	0.187 Inch
Terminal Style	Standard
Terminal Type	Disconnect
Thickness	0.02 Inch
UL File Number	E70512