

# LED Flexi Strip - S-Type

**NEW!**




## LED Flexi Strip - S-Type


Part Code	F5-11-35-1-60-F6S-20-10M-FP	F5-11-35-1-72-F6S-20-10M-FP
Lumen Output	960lm	1152lm
Input Voltage	12Vdc	12Vdc
Power per metre	10W	12W
Cutable Length	50mm	50mm
LED Qty	60 per mtr	72 per mtr
Beam Angle	120°	120°
IP	IP20	IP20
CCT	6500K	6500K
Dimensions	5000 x 8mm (3mm narrowest point)	5000 x 6mm (3mm narrowest point)



### 60 LEDs per metre

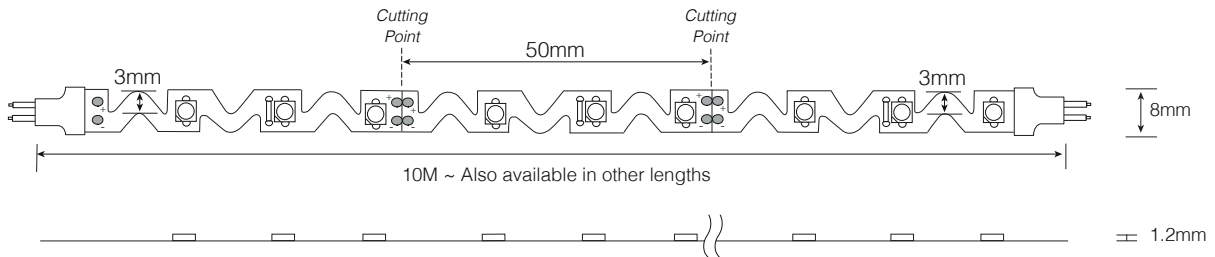

### 72 LEDs per metre

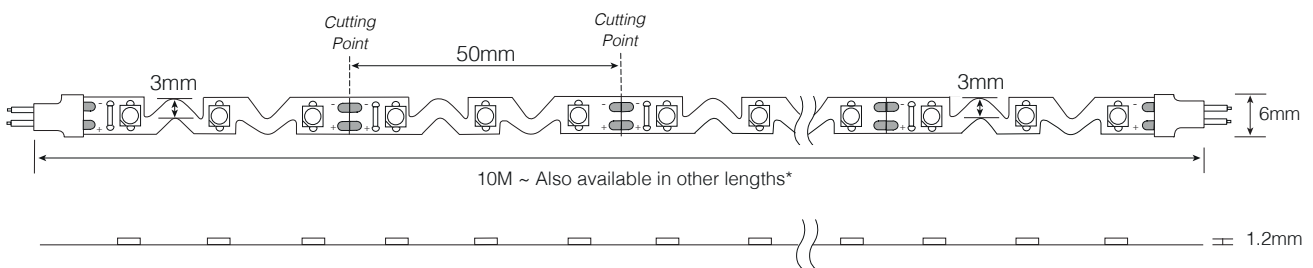

\*Maximum single length 2M

