

o Flat Cable Connectors SEK

o har-mik®

o D-Sub

o InduCom

Applications



## Product details

**09 18 514 5324**


**IDC male connector**

Connector size	14 contacts
Termination	Straight solder pin
Profile	Low-profile male header
Moulding	Standard Material
Termination length	2.9 mm
Performance level	AU-0.76•m [30• Inch]
RoHS compliant	Yes

### Available Downloads

Title	Format	
Data sheet	PDF	download
CAD data 2D	DXF	download
CAD data 3D	IGES	download
CAD data 3D	STEP	download

**Inquiry**

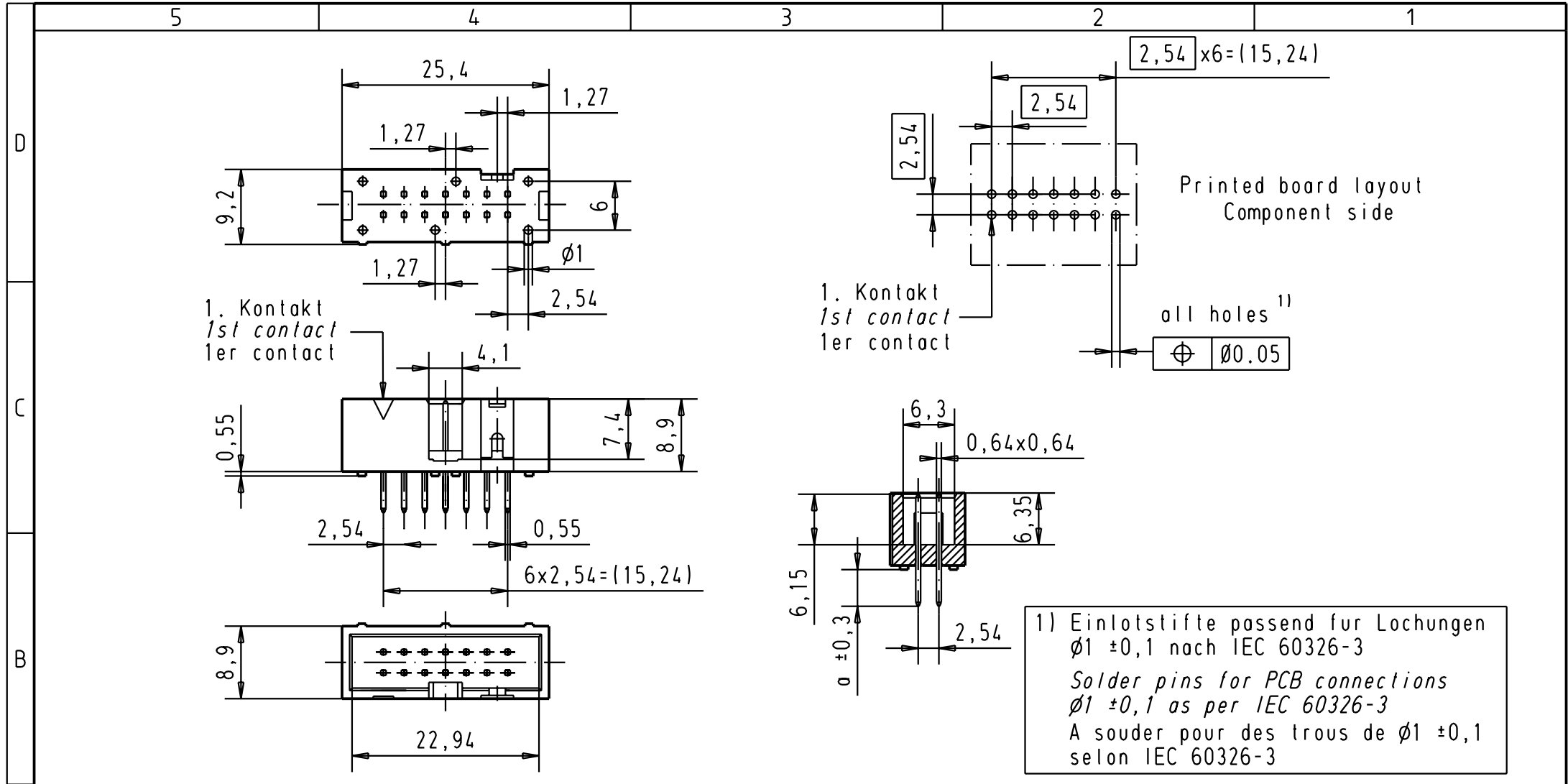

1) Einlotstifte passend für Lochungen  $\phi 1 \pm 0,1$  nach IEC 60326-3  
 Solder pins for PCB connections  $\phi 1 \pm 0,1$  as per IEC 60326-3  
 A souder pour des trous de  $\phi 1 \pm 0,1$  selon IEC 60326-3

A	09185147322	3	4,5	All Dimensions in mm Original Size DIN A 4	Techn. Character.			Nicht tolerierte Masse! Free size tolerances	
	09185146322	2	4,5						
	09185145322	0,76 $\mu\text{m Au}$	4,5						
	09185147324	3	2,9		Detail.	01-FEB-00	JB	1,5:1	SEK 18 Male connector 14 poles low profile with straight pins
	09185146324	2	2,9		Insp.				
	09185145324	0,76 $\mu\text{m Au}$	2,9	31502	03-JUN-03	JB	Stand.		
Bestell-Nr. Part-No. Reference	Anforderungsstufe performance level Niveau de qualite	a	29778 26570	25-APR-02 01-FEB-00	CV JB	HARTING EURL F-95972 Paris		TB 0918514x32x	Blatt / page 1 / 2
			Mod.	Dat.	Name			Sub.	