




Produktname | *Product name*: X20
 Artikelnummer | *Part Number*: 1600-0154
 Anfragenummer | *Inquiry Number*: AN2015332AA
 Ersteller / Datum | *Creator / Date*: LHE / 2016-08-19

Version	Change	Date	Name
V0	---	2016-08-19	LHE

Leuchte / light

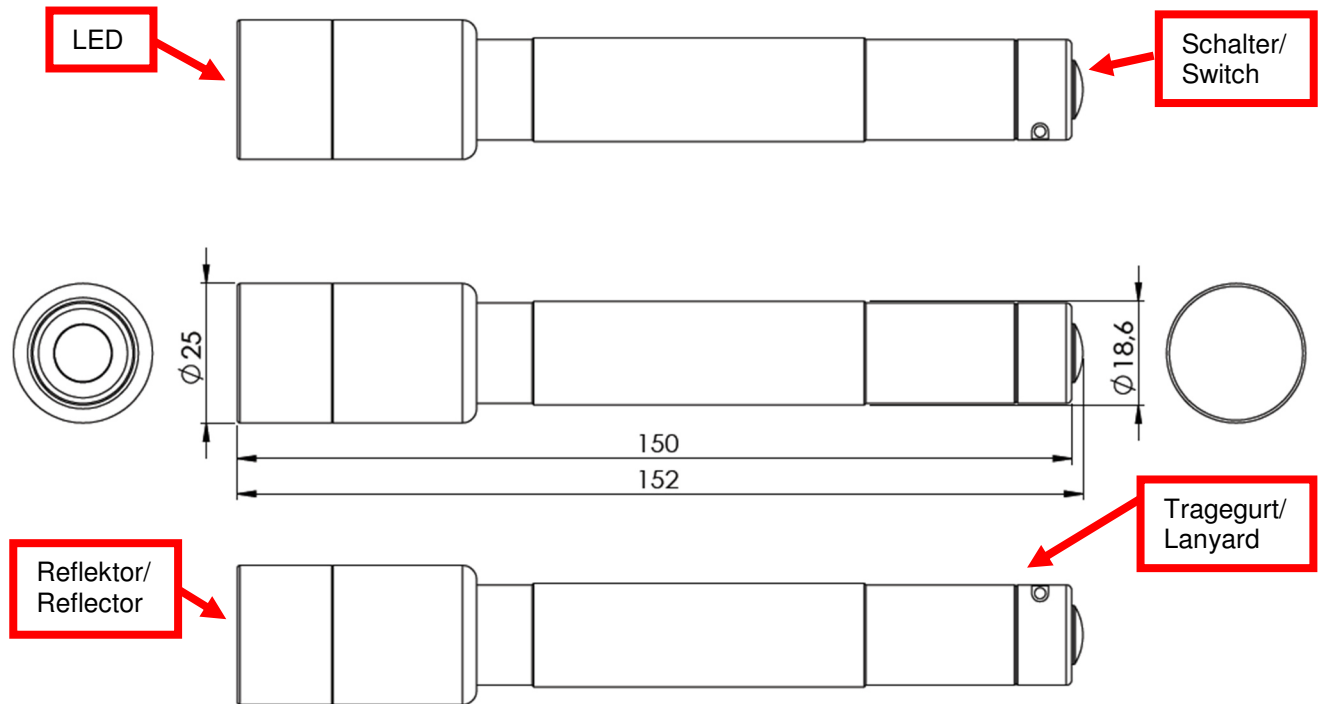

Technische Daten der Leuchte / technical data of the light:


Haupt-LED-Leuchtmittel:	0.36W LED	Main LED illuminant:	0.36W LED
Schalterfunktion:	1. An	Switch function:	1. On
	2. Aus		2. Off

Lichtstrom: [Lumen]	25lm	Luminous flux (light output): [Lumen]	25lm
Leuchtdauer:	ca. 30h	Run time:	approx. 30h
Leuchtweite:	ca. 65m	Beam distance:	approx. 65m
Maximale Lichtstärke: [Candela]	900cd	Peak beam / luminous intensity: [Candela]	900cd
Maximale Beleuchtungsstärke: [Lux]	900lx (Abstand: 1m)	Peak beam illuminance: [Lux]	900lx (Distance: 1m)
Risikogruppe (EN 62471; Bewertet nach DIN IEC/TR 62778 Anhang C.2)	2	Risk group (EN 62471; Assessed with TR 62778 Annex C.2)	2

Benötigte Zellen:	2x AA Mignon 1.5V Batterie/Batterien (Alkaline; LR6/AM3/MN1500)	Battery:	2x AA Mignon 1.5V battery/batteries (Alkaline; LR6/AM3/MN1500)
Schutzart des Gehäuses:	IPx4	Degree of protection by the enclosure:	IPx4
Gehäusematerial:	Aluminium	Housing material:	Aluminium
Betriebstemperatur:	-10°C...25°C	Operating temperature:	-10°C...25°C
Lagertemperatur:	-10°C...50°C (Nur Alkaline Batterie/Batterien) -20°C...70°C (Nur Lampe)	Storage temperature:	-10°C...50°C (Alkaline battery/batteries only) -20°C...70°C (Torch only)
Empfohlene Lagerbedingungen: (Nur Alkaline Batterie/Batterien)	Temperatur: 5...25°C Luftfeuchtigkeit: 45...75%	Recommended storage conditions: (Alkaline battery/batteries only)	Temperature: 5...25°C Rel. humidity: 45...75 %
Approbationen:	CE	Approvals:	CE
Gewicht:	65.5g nur die Lampe 110g mit 1 x Batterie (wie oben beschrieben)	Weight:	65.5 only the torch 110g with 1 x battery (as described above)
Lieferumfang:	- 2 x Batterie (wie oben beschrieben) - Tragegurt	Shipment:	- 2 x battery (as described above) - Lanyard
Verpackung:	Blister-Verpackung	Package:	Blister shell