


Datasheet

RS Coaxial Cable, Black PVC Sheath, 100m, URM203, 7.3mm OD

Stock number: 665-5842

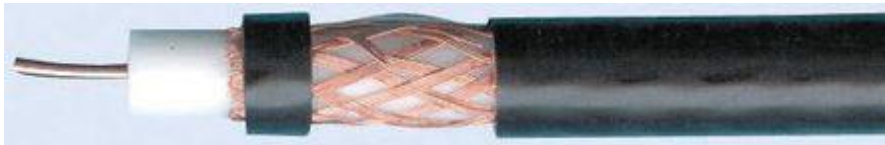

Product Description

Application:

For communication and signal control systems.


Multi-construction

1

Construction

Single Construction	Bare Copper
Stranded Dia.(mm)	1.12±.02
Insulation	Gas injection Foam PE
Thickness	2.01
Insulation Dia.(±0.2mm)	5.15
Insulation Color	Natural
Braiding	Bare Copper
Construction (stranded)	0.12±0.008×16×6
Braiding coverage	65%
Jacket	PVC
Thickness(mm)	0.90
Dia.(±0.2mm)	7.30
Jacket Color	Black

Design

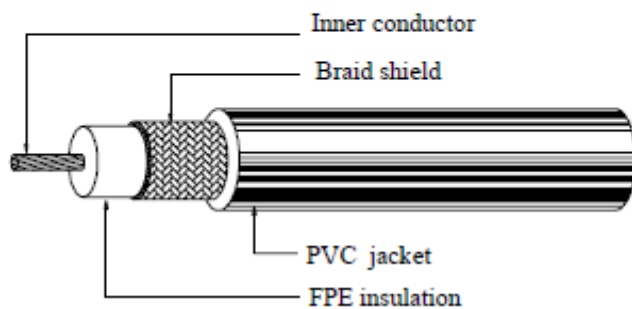

Electrical Characteristics

DC Resistance inner core .at 20 °C (Ω /Km)	<19.2
Min.Insulation DC Resistance at 20 °C (M Ω *KM)	500
Rated Temperature(°C)	80
Rated Voltage(V)	30
Capacitance(pF/m)	52±4
Velocity ratio (%)	82%
Impedance(Ω)	75±3