


C810 HSS

DORMER

Dormer standard

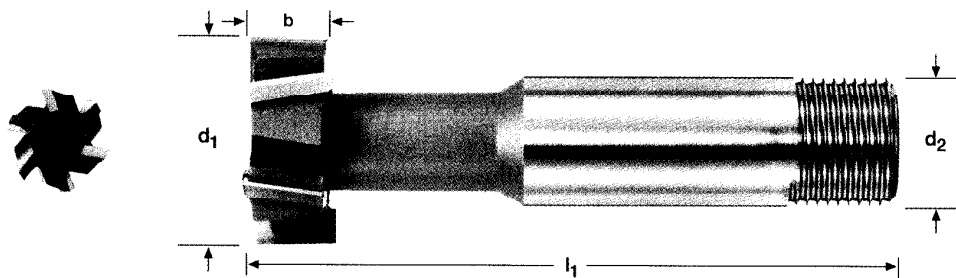

T-Slot Cutters

Type	N
Surface Treatment	Bright
Diameter Tolerance	d11
Flute Geometry	Alternate Right & Left Hand Angled Teeth. Right Hand Cutting
Shank	Threaded parallel shank, acc. to DIN 1835 D, tol. h8
Application	To mill "T" shaped heads in existing milled slots. Generally used for bolt slots

Entry Code	d ₁ Ø mm	b mm	d ₁ Ø Inch /"	T DIN 650	l ₁ mm /"	l ₂ mm	d ₂ Ø mm /"	d ₃ Ø mm /"	Z
C8106.0	12,50	6,00		6,0	57,0	11	10,0	5,00	6
C8101/4	14,68	6,35	37/64 x 1/4	1/4	60,5	14	12,7 - 1/2	6,35	6
C8108.0	16,00	8,00		8,0	61,0	13	10,0	7,00	6
C8105/16	17,86	7,94	45/64 x 5/16	5/16	65,0	17	12,7 - 1/2	7,15	6
C81010.0	18,00	8,00		10,0	65,0	17	12,0	8,00	6
C81012.0	21,00	9,00		12,0	69,0	20	12,0	10,00	6
C8103/8	21,03	9,13	53/64 x 23/64	3/8	68,5	19	12,7 - 1/2	8,75	6
C8107/16	24,21	10,72	61/64 x 27/64	7/16	73,0	22	12,7 - 1/2	9,50	6
C81014.0	25,00	11,00		14,0	79,0	23	16,0	12,00	6
C8101/2	27,38	11,91	1.5/64 x 15/32	1/2	76,0	24	12,7 - 1/2	11,00	6
C81016.0	28,00	12,00		16,0	76,0	23	16,0	13,00	6
C8105/8	33,73	14,68	1.21/64 x 37/64	5/8	101,5	30	25,4 - 1.	14,30	8
C81018.0	32,00	14,00		18,0	98,0	27	25,0	15,00	8
C81020.0	36,00	16,00		20,0	100,0	30	25,0	17,00	8
C8103/4	38,50	17,46	1.33/64 x 11/16	3/4	109,5	35	25,4 - 1.	17,45	8
C81022.0	40,00	18,00		22,0	108,0	33	25,0	19,00	8
C8107/8	43,26	20,24	1.45/64 x 51/64	7/8	117,5	40	25,4 - 1.	20,65	8
C8101	49,61	23,02	1.61/64 x 29/32	1.	127,0	47	25,4 - 1.	23,80	8