


Datasheet

Yellow Insulated Crimp Receptacle

RS Stock number [239-4240](#)

Dimensions: (mm)

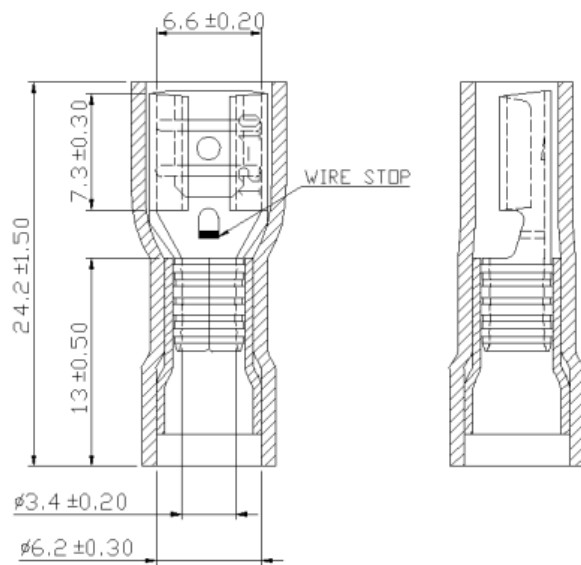

Specifications

- Maximum Electric Current: AWG: 12 | 10 AMP: 20 | 24
- Maximum Electrical Rating: 75°C 600 Volts Max
- Insulation Material: Vinyl
- Insulation Colour: Yellow
- Terminal Material: Brass
- Wire Range: 26-22 AWG (0.2-0.5mm²)
- Terminals Surface Treatment: Tin Plated
- Double Crimp: With Copper Sleeve on Barrel
- Terminal Thickness: 0.4mm