

VS-BH-M12FS-8CON-RJ45/180

Order No.: 1405060



Control cabinet feed-through, M12, 8-pos., A-coded on RJ45 socket,
socket input 180°, IP65/67



Ethernet

Commercial data

EAN	 4 046356 298551
Note	Made-to-order
Pack	1
Customs tariff	85369010
Country of Origin	DE
Catalog page information	Page 295 (PC-2011)

Product notes

WEEE/RoHS-compliant since:
06/06/2007



Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

Technical data**Mechanical characteristics**

Number of positions	8
Color	black
Ambient temperature (operation)	-25 °C ... 85 °C

Material data

Inflammability class according to UL 94	V0
---	----


Housing material	PA
Contact material	Copper alloy
Degree of protection	IP65/IP67

Electrical characteristics

Number of positions	8
Transmission characteristics (category)	CAT5 (IEC 11801:2002), CAT5e (TIA 568B:2001)
Rated current	1 A

Drawings

Dimensioned drawing

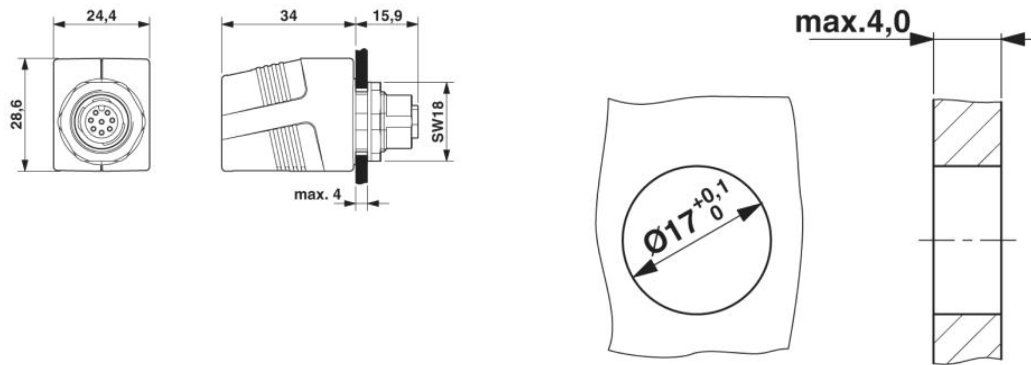

Panel cutout