



Deep groove ball bearings, single row, unsealed

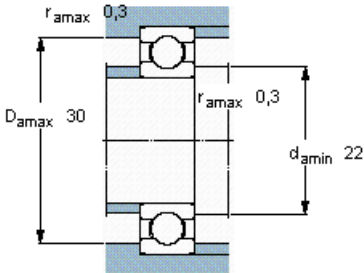

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
20	32	7	4,03	2,32	0,104	45000	28000	0,018	61804

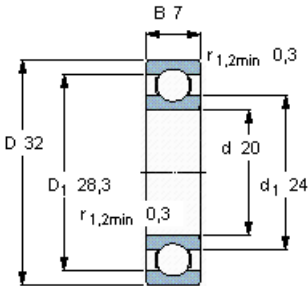

Calculation factors

k_f 0,015
 f_0 15