


Verbatim LED PAR16 GU10 9W 3000K Warm White 465 LM DIM

- GU10 Socket
- 220 - 240 V Voltage
- 25,000 hours Lifetime
- Dimmable
- 86% Energy Saving
- Equivalent to 66W incandescent bulb

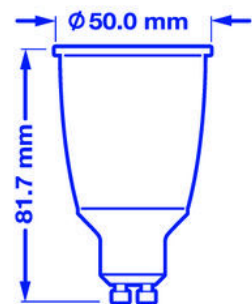


Product Number	52233
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	9
Wattage Equivalent (W)	66
Voltage (V)	220 - 240 V
Dimmable	yes
Power Factor	0.7
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	81.7
Diameter (in mm)	50
Weight (g)	145
Photometric Data	
Luminous Flux 90° Cone (lm)	465
CRI	80
CCT (K)	3000
Luminous Intensity (cd)	2000
Beam Angle (°)	25
Luminous Efficacy (lm/W)	52
Lifetime (hrs)	25,000
Switching Cycle	60,000



02/07/2014

Energy Rating

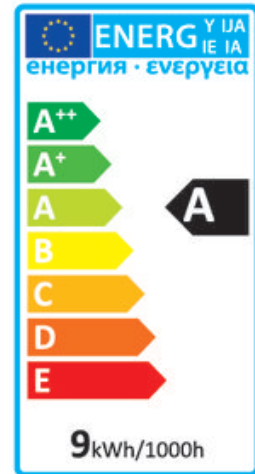

Technical Packaging Details

Barcode

023942522331

EAN 128

(02)00023942522331(37)20(91)53

EAN 14

50023942522336

Pack Dimensions(HxWxL)

107 x 66 x 66

Pack Weight

176

MOQ

10

Carton Dimensions (HxWxL)

336 x 139 x 121

Cartons/Pallet

136

Layers/Pallet

8

Units/Pallet

1360

02/07/2014