

## Mini-Lynx Fast Start Spiro

ML SPIRAL 827 E27 12W SLV

0035212

### Range features



CE

### PRODUCT OVERVIEW

Ordering number	0035212
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Spiral
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	SPIRAL
EAN code	5410288352121
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	600
Efficacy (Rated) (lm/w)	50
Watt (Nominal) (W)	12
Equivalent watt (W)	50
Voltage (V)	220-240

# Mini-Lynx Fast Start Spiro

ML SPIRAL 827 E27 12W SLV

**0035212**

## DATA TABLE

### General data

<b>Dry applications use only</b>	Yes
<b>Technology</b>	Compact Fluorescent
<b>Ordering number</b>	0035212
<b>Energy saving lamp</b>	Yes
<b>Average life (Rated) (h)</b>	10000
<b>Energy class</b>	A
<b>Average life (Nominal) (h)</b>	10000
<b>Lamp finish</b>	Frosted
<b>Lamp shape</b>	Spiral
<b>Dimmable</b>	No
<b>Cap/Base</b>	E27
<b>Type</b>	SPIRAL
<b>EAN code</b>	5410288352121
<b>E-number FI</b>	4940401
<b>E-number SE</b>	8357559
<b>Long description</b>	
<b>Product name</b>	ML SPIRAL 827 E27 12W SLV
<b>Lamp mercury content (mg)</b>	<2
<b>Starting time (max) (s)</b>	<1.0
<b>Warm-up time to 60% of full light (max) (s)</b>	<40
<b>Control gear required</b>	NO
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	30000
<b>Special purpose lamp</b>	No
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	10
<b>Optimal operating condition (°C)</b>	25

### Optical data

<b>Light colour</b>	827 Homelight
<b>CRI (Ra)</b>	80
<b>Colour temperature (K)</b>	2700
<b>Luminous flux (Rated) (lm)</b>	600
<b>Lumen maintenance at end of nominal life (%)</b>	65
<b>Luminous flux (Nominal) (lm)</b>	600

## Mini-Lynx Fast Start Spiro

ML SPIRAL 827 E27 12W SLV

0035212

### Electrical data

<b>kWh per 1000 hours burning time</b>	12
<b>Efficacy (Rated) (lm/w)</b>	50
<b>Watt (Rated) (W)</b>	12
<b>Watt (Nominal) (W)</b>	12
<b>Equivalent watt (W)</b>	50
<b>Voltage (V)</b>	220-240
<b>Lamp power factor</b>	=0.55

### Physical data


<b>Weight (kg)</b>	0.04
<b>Lamp Length (mm) - C/L</b>	95±3
<b>Max. Lamp Diameter (mm) - D</b>	45±1
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	11.50 x 4.80 x 4.80
<b>Outer package dimensions (L x W x H) (cm)</b>	26.00 x 13.50 x 11.50

## Mini-Lynx Fast Start Spiro

ML SPIRAL 827 E27 12W SLV

0035212

### TECHNICAL DRAWINGS

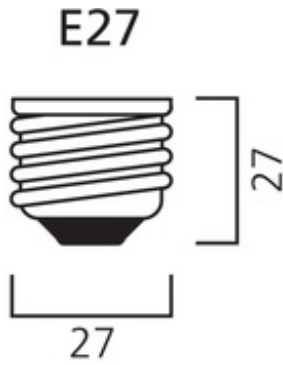

### ENERGY LABEL

