

Product Information



3640ITP125P63 Flat

EAN 4031582337358


Swivel castor, housing made of heavy pressed steel, bright zinc plated, blue passivated, precision ball bearing swivel head, sealed, wheel axle with nut, plate fitting.

Wheel centre made of Aluminium, Tread: Polyurethane, casted, precision ball bearing

Technical Data

Wheel diameter	125 mm
Width of Tread	50 mm
Size of Plate	137 x 105 mm
Plate hole centres	105 x 80/75 mm
Plate hole	11 mm
Offset	55 mm
Swivel Interference	235 mm
Overall height	178 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	2.941 kg
Swivel Radius	117.5 mm
Hardness of tread	A 92 Shore
Load capacity	500 kg
Load capacity (static)	1000 kg

Roll performance	+	+	+	+	+
Movement noise	+	+	+	+	+
Attrition	+	+	+	+	+
Corrosion resistance	+	+	+	+	+

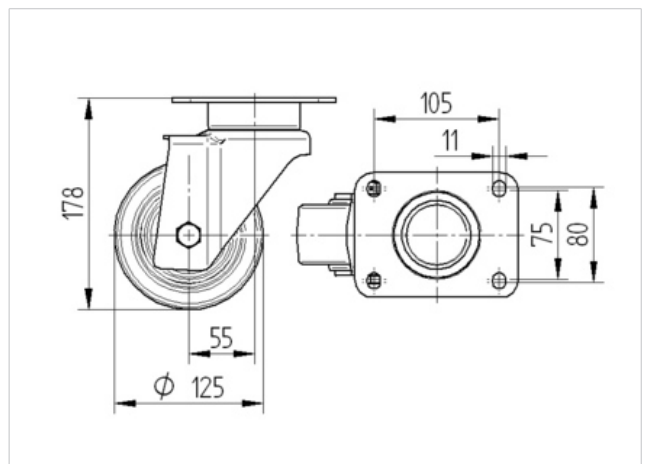

3640ITP125P63 Flat

EAN 4031582337358

