


Verbatim LED PAR16 GU10 4W 2700K Warm White 250 LM


- GU10 Socket
- 220 - 240 V Voltage
- 20,000 hours Lifetime
- 89% Energy Saving
- Equivalent to 38W incandescent bulb

Product Number	52607
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	4
Wattage Equivalent (W)	38
Voltage (V)	220 - 240 V
Dimmable	no
Power Factor	0.40
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	55.3
Diameter (in mm)	49.8
Weight (g)	56
Photometric Data	
Luminous Flux 90° Cone (lm)	250
CRI	80
CCT (K)	2700
Luminous Intensity (cd)	650
Beam Angle (°)	35
Luminous Efficacy (lm/W)	62.5
Lifetime (hrs)	20,000
Switching Cycle	100,000

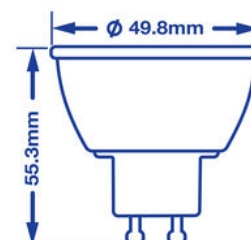

02/07/2014

Photometric Diagrams

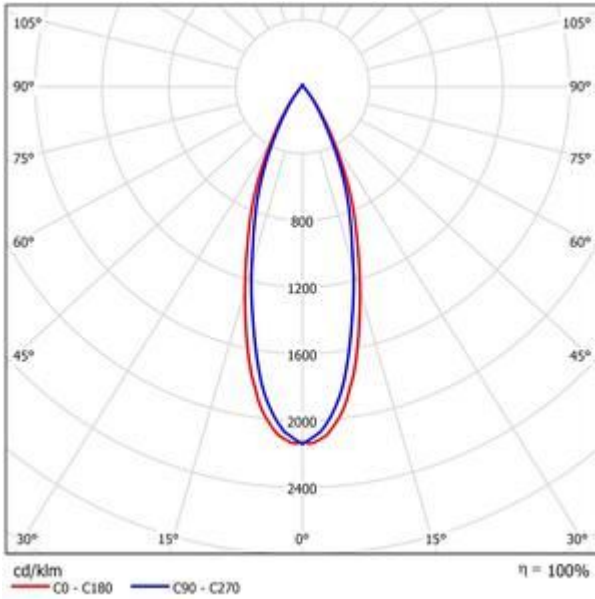


Distance [m]	Cone Diameter [m]	E(0°) [lx]	E(C90) [lx]	E(C0) [lx]
0.5	0.29 0.33	2739	1225	1178
1.0	0.58 0.66	685	306	294
1.5	0.88 0.99	304	136	131
2.0	1.17 1.32	171	77	74
2.5	1.46 1.65	110	49	47
3.0	1.75 1.98	76	34	33

Distance [m] Cone Diameter [m] Illuminance [lx]

— C0 - C180 (Half-value Angle: 36.6°)
— C90 - C270 (Half-value Angle: 32.6°)

Energy Rating

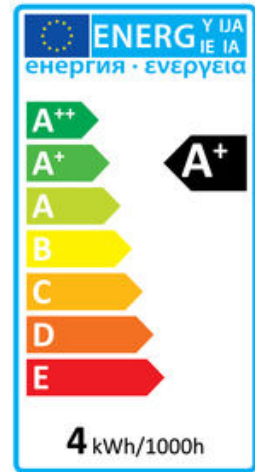

Technical Packaging Details

Barcode

023942526070

EAN 128

(02)00023942526070(37)04(91)204

EAN 14

50023942526075

Pack Dimensions(HxWxL)

145 x 103 x 51

Pack Weight

80

MOQ

4

Carton Dimensions (HxWxL)

160 x 117 x 223

Cartons/Pallet

150

Layers/Pallet

5

Units/Pallet

600

02/07/2014