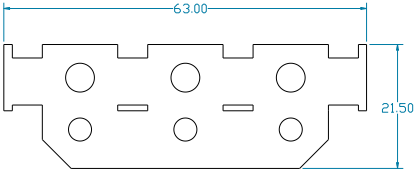
 
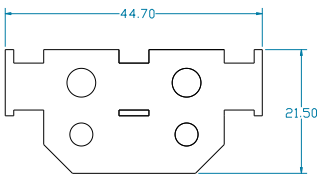
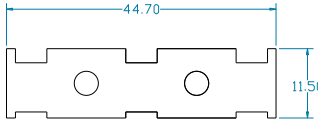
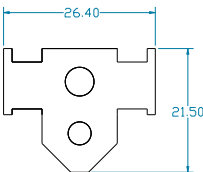
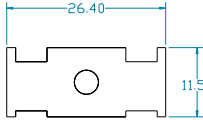
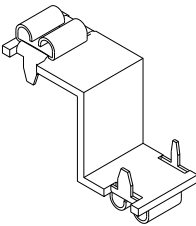


PARRALEL LINKS		
Specification	Positive Links	Negative Links
M4 Screws – Tighten to 1.5NM	Par4 Link	Par4 Link
Friction Lock		
Protrude 21.50mm		
Brass – Tin Plated		
	Par3 Link	Par3 Link
		
	Par2 Link	Par2 Link
		
SERIE LINKS		
Specification	Serie Link	
M4 Screws – Tighten to 1.5NM		
Friction Lock		
Protrude 11.50mm		
Centre Tap point		

Notes: Refer to the User Manual and datasheets for information on how to connect modules in parallel or in series.