




Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearir
mm			kN		r/min		-
45,242	73,431	19,558	53,9	75	6700	9500	LM 102949/910/Q

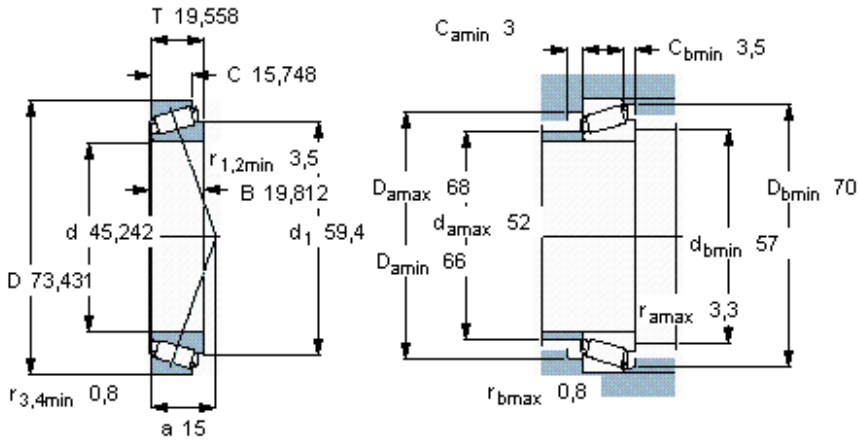

Calculation factors
 $e = 0,3$
 $Y = 2$
 $Y_0 = 1,1$