



No.390, Yong He Road,
Shanghai 200072, China

TECHNICAL DATA SHEET CABLE ASSEMBLY

PART NUMBER :R284C0351050

Issue : NA

Date : NA


Customer :

Specification : NA

Issue : NA

Date : N/A

All dimensions are in mm

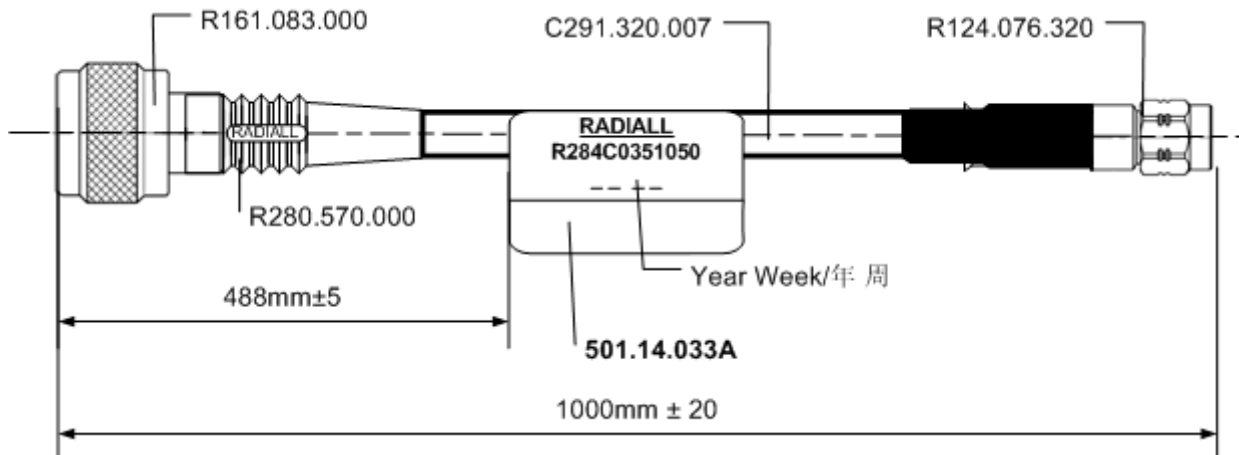

Connectors designation :	Connector 1 : N straight plug full crimp type cable 5/50 D (R161.083.000)	Connector 2 : SMA straight plug full crimp type cable 5/50 D (R124.076.320)
Cable designation :	Flexible Cable 5/50D (RG142) C291.320.007	
Nominal length :	Lg: 1000 mm	
Cable colour :	Brown	
Outer diameter :	4.95 mm	
Accessories :	Plastic Boots (R280.570.000)	

ELECTRICAL CHARACTERISTICS :

High Frequency

Characteristic impedance : 50 ± 2 Ohms

Frequency range : DC-11GHz

Insertion Loss : 1.01 dB max @ 3GHz & 20°C

VSWR. : TBT

Low Frequency

Insulation Resistance : 5000 MOhms min

Voltage Rating : 335 Veff max

MECHANICAL CHARACTERISTICS :

Recommend min. bend radius : 25 mm

Cable crush resistance : NA

Life (connectors) : 100 cycles

ENVIRONMENTAL CHARACTERISTICS :

Operating temperature range : -55° C to +135° C

Remark : NA

Attachment : R161.083.000-TDS , R124.076.320-TDS

C291.320.007 (RG142)-TDS

Cable Assembly is RoHS compliant.

CUSTOMER'S APPROVAL

Service or
Company's stamp

Name
Date

Jacob	A	2007-6-11	Creation	Willy
Name	Issue	Date	Modification	Checked by