


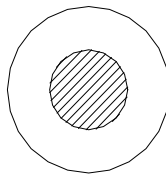

Product Name:	UL1430 26AWG
Product Discription:	UL1430 26AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		300V			Conductor		Stranded Tinned Copper					
Rated Temperature:		105℃			Size(AWG)		26					
Reference Standard:		UL758,UL1581			Construction(±0.008mm)		7/0.16					
Cross Section					Stranded Dia.(mm)Ref.		0.48					
					Insulation Material		XLPVC					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.38					
					Insulation Dia.(±0.10mm)		1.30					
Marking					Remark:							
AWM XLPVC 1430 26AWG 105℃ 300V Horizontal flame Retardant AWM XLPVC 105℃ 300V I A FT2 E214859 YANG TAI					8739901 Red		8739905 Blue		8739923 Grey		8739927 Violet	
					8739898 Black		8739914 White		8739911 Yellow			
					8739908 Brown		8739917 Green		8739920 Orange			
Applications					Characteristics					Customer Approve		
For internal wiring of electronic and electrical equipment					Test Item			Standard Value			Seal & Stamp	
					Test Material			XLPVC(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			150(MAX)				
Version	Description	Drawn by	Approved by	Date							Signature:	
0	New document issue	Huang	Jason	14/04/2015								
											Date:	