





AUXILIARY SWITCH CHANGEOVER CONTACTS
TYPE HQ (7MM) ACCESSORY FOR 3VA-BREAKER



| Model | | |
|---|-----------------|------------------|
| product brand name | | SENTRON |
| Product designation | | auxiliary switch |
| General technical data | | |
| Thermal current | A | 6 |
| Overvoltage category | | III |
| Voltage | | |
| Insulation voltage / Rated value | V | 690 |
| Surge voltage resistance / Rated value | kV | 4 |
| Operating voltage | | |
| • at AC / at 50 Hz / Rated value / minimum | V | 240 |
| • at DC / Rated value / minimum | V | 250 |
| Wire stripping length | mm | 15 |
| Connectable conductor cross-section / maximum | mm ² | 1.5 |
| Tightening torque / with screw-type terminals / maximum | N·m | 0.5 |
| Height | mm | 56 |
| Width | | |

| | | |
|---------------------|----|---------------|
| • Note | | 1 slot (7 mm) |
| Depth | mm | 30 |
| Net weight | g | 30 |
| Degree of pollution | | 3 |

| General Product Approval | EMC | Declaration of Conformity | Test Certificates |
|--|--|---|---|
|  CCC |  VDE |  |  EG-Konf. |

[sonstig](#)

[Typprüfbescheinigung/Werkszeugnis](#)

| |
|-------|
| other |
|-------|

[sonstig](#)

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3VA99880AA12>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3VA99880AA12/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA99880AA12

CAX-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

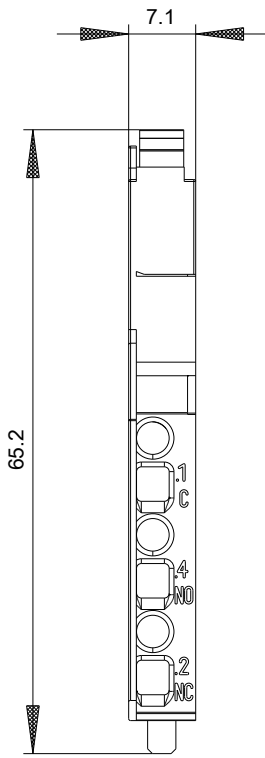

last modified:

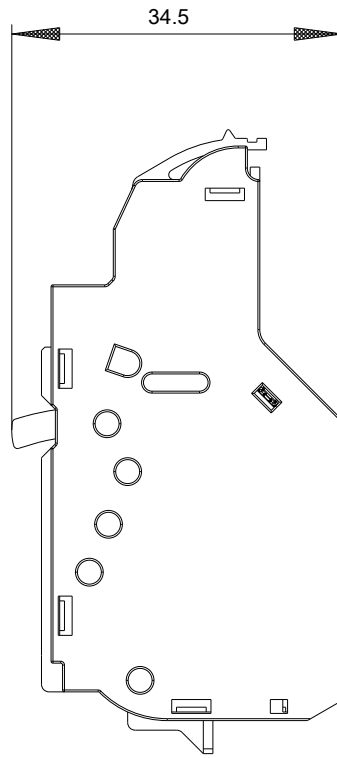

20.07.2015