


Deep groove ball bearings, double row



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
30	62	20	26	20,8	0,88	17000	9500	0,26	4206 ATN9

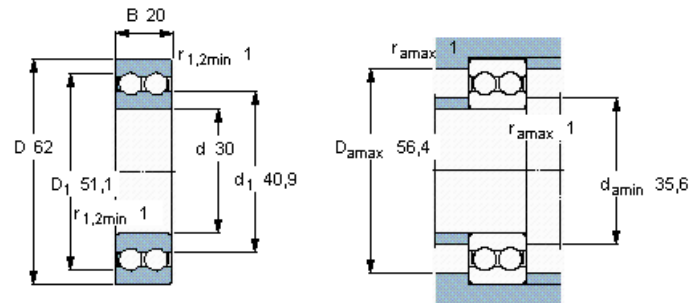

Calculation factors

k_f 0,05
 f_0 14