

# Housing - HC-B 24-KML-H-O1PG29 - 1460250

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B24 coupling housing, with single locking latch, height: 80.5 mm, with 1 x Pg29 gland, straight cable outlet



## Key commercial data

Packing unit	10 pc
GTIN	 4 046356 696104
Weight per Piece (excluding packing)	22.22 g
Custom tariff number	85389099
Country of origin	Germany

## Technical data

### Dimensions

Height	82 mm
Width	43 mm
Length	120 mm

### Ambient conditions

Degree of protection of housing (IP)	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

### General

Note	For contact inserts HC-B24, BB46, BBB64, D64, DD108, M
Type	B24
Housing type	Coupling housings
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	Straight
Screw connection	none
Type of the screw connection	1x Pg29
Housing material	Aluminum die-cast

# Housing - HC-B 24-KML-H-O1PG29 - 1460250

## Technical data

### General

Housing surface material	Powder-coated, gray
Seal material	NBR
Material lock	Stainless steel, handle: PA
Material grip body interlock	PA
Assembly instructions	For half and full screw connections

## Classifications

### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440202

### ETIM

ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

Approvals submitted

# Housing - HC-B 24-KML-H-O1PG29 - 1460250

## Approvals

---

### Approval details

EAC
-----

## Accessories

### Accessories

#### Full screw connection

Cable gland - G-INS-PG29-M68N-PNES-GY - 1411146



Cable gland, Cable gland material: Polyamide, External cable diameter 18 mm ... 25 mm, Shielding: No, Connecting thread: Pg29, Color: silver grey

---

Cable gland - G-INS-PG29-M68N-NNES-S - 1411176



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 18 mm ... 25 mm, Shielding: No, Connecting thread: Pg29, Color: silver

---

Cable gland - G-INSEC-PG29-M68N-NNES-S - 1411201



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 18 mm ... 25 mm, Shielding: Yes, Connecting thread: Pg29, Color: silver

---

### Plug for cable screw gland

Filler plugs - HC-BS-PG29 - 1674532




Filler plugs, for Pg screw connections, type Pg29

---

## Drawings

## Housing - HC-B 24-KML-H-O1PG29 - 1460250

Dimensioned drawing

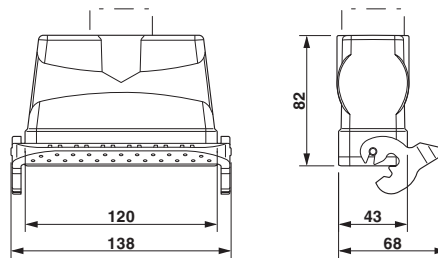

Dimensional drawing

---

Phoenix Contact 2015 © - all rights reserved  
<http://www.phoenixcontact.com>