

T 221



Euromas
 Euromas enclosure, ABS

Order no.: 03221000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request

Protection class

Depending on the model: IP 65 or IP 66/DIN EN 60529

Enclosure material


Enclosure material: ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details, see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: * = Available on request. Accessories: see following pages.

SV = version with quick-release fastener

c3 = Ingress protection acc. to DIN EN 60529

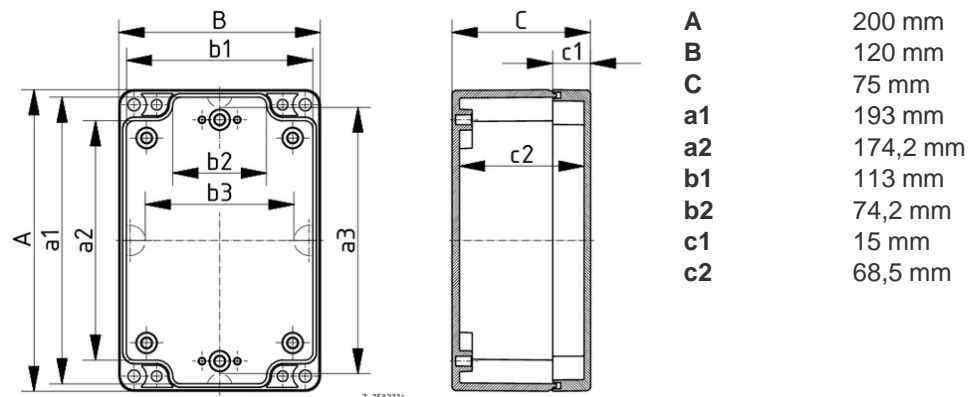

Technical drawings

Catalogue drawing in DXF format:

[03221000_T-221.dxf](#) (707 KB)

Catalogue drawing in PDF format:

[03221000_T-221.pdf](#) (74 KB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[03221000_T-221-G.dxf](#) (354 KB)

Chapter download

[Euromas-ABS_Polycarbonate_GB.pdf](#) (531 KB)

Accessories



Mounting plates, laminated paper (Pertinax), galvanised steel for version 260

22000700

[M](#)

For EM/ET 221, EM/ET 237, M/T 221, M/T 237



Knurled screws

22003100

[RD](#)

For M/T 210-215, M/T 217, M/T 220-227, M/T 231



Rubber feet, plug-in

22003300

[F](#)

For M/T 208-260



Silicone seal for lid

22003900

[SIL](#)

For M/T 221, M/T 237



Wall brackets on rear, screw-on, polycarbonate

22004900

[WL](#)

For M/T 210-243, M/T 246-253



DIN rails DIN EN 60715 TH 15

22002100

[TS 15](#)

For M/T 221-223, M/T 237



DIN rails DIN EN 60715 G 32

22002110

[TS 32](#)

For M/T 221-223, M/T 237



DIN rails DIN EN 60715 TH 35

22002115 [TS 35](#)

For M/T 221-223, M/T 237



Threaded inserts for mounting bosses

59002810 [DODGE M3x6,5](#) ND = 4.0 x 6.5
59002820 [DODGE M4x9,5](#) ND = 5.4 x 9.5

