




### Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshows
- Support

United States > All 3M Products > Market Segments > Electronics, Electrical, and Communications > Electrical Products > Electrical Commercial and Industrial > Products > \_\_\_\_\_

## 3M™ Scotchlok™ Male Disconnect Nylon Insulated, 100/bottle, MNG18-250DMX

3M ID 80611464316 UPC# 00051128587850 3M Product Number MNG18-250DMX

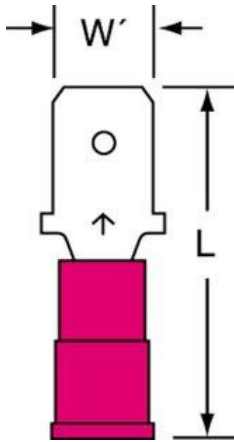

Male Disconnect Nylon Insulated, 100/bottle, MNG18-250DMX

Overview

Documentation

#### Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.065 Inch
Barrel Style	Insulation Grip
Brand	Scotchlok
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
Fastener Orientation	Male
Insulation Material	Nylon
Length (L)	0.92 Inch
Male Tab Width (W')	0.250 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	100 per bottle
Pad Width	0.25 Inch
Terminal Style	Standard
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512