


Part no. : 7612

Receptacle



switched, with mechanical DUO-interlock; can be padlocked

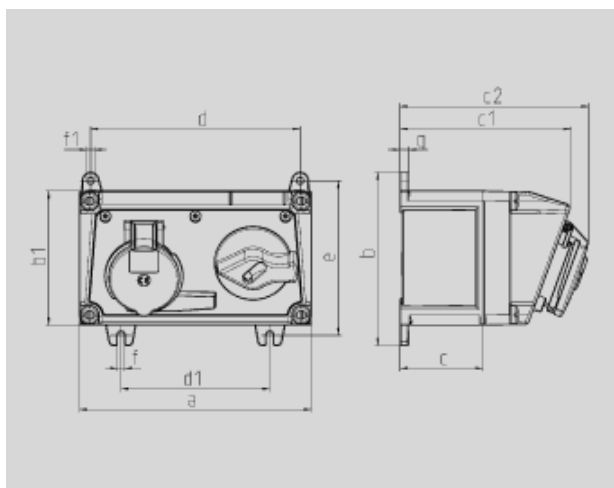

Drawing 1 MB 550 Dim. in mm	Amp. Poles	16			32		
		3	4	5	3	4	5
a		225	225	225	225	225	225
b		168	168	168	168	168	168
b1		130	130	130	130	130	130
c		80	80	80	80	80	80
c1		166	166	166	166	166	166
c2		182	183	183	193	193	193
d		204	204	204	204	204	204
d1		145	145	145	145	145	145
e		150	150	150	150	150	150
f		7	7	7	7	7	7
f1		Ø7	Ø7	Ø7	Ø7	Ø7	Ø7
g		8	8	8	8	8	8

Article-group : **1100**

voltages : 230V

rated current : 32A

pole : 3 pole

IP protection types : 44

position of ground contact : 6h

weight : 1482

PART NUMBERS

		V	110V	230V	400V	500V	>50-500V	
Hz			50,60	50,60	50,60	50,60	100-300	300-500
colour								
amp.								
16 A	3		7602	7603				
	4			7604	7605	7606		
	5				7607			
32 A	3		7611	<u>7612</u>				
	4			7613	7614	7615		
	5				7616			