


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
25	47	12	11,9	6,55	0,275	32000	16000	0,080	6005-2Z *

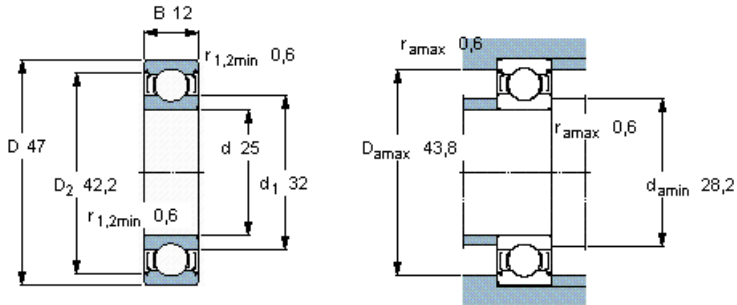

Calculation factors

k_r 0,025
 f_0 14