


Deep groove ball bearings, single row

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
65	140	33	97,5	60	2,5	10000	6700	2,10	6313 *

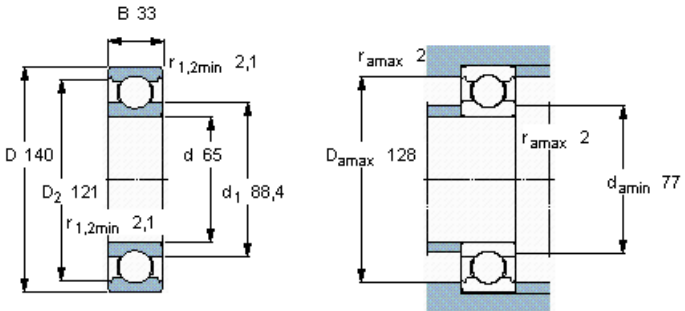

Calculation factors

k_r 0,03
 f_0 13