




ENGLISH

Datasheet

Stock No: 777-4972

RS Pro 3 Core Screened CY Control Cable

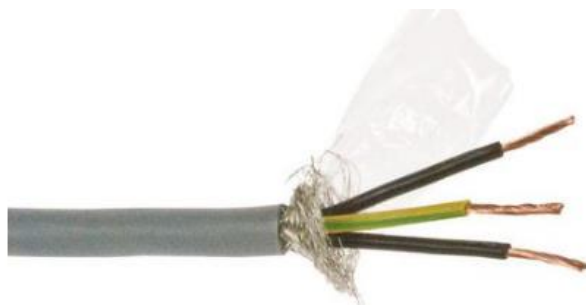

Part NO: #5219

Product Code: RGW-1928

Product Description

Application:

For internal or external wiring of warning network systems.

Multi-construction

3 Cores

Construction

3 Cores

Construction

Stranded Dia.(+/-0.08mm)

Insulation

Thickness

Insulation Dia.(mm)

Insulation Color

Lay Length

Direction of Lay

Mylar spiral

Braiding

Construction

Braid lay(mm)

Outer Jacket

Thickness(mm)

Dia.(mm)

Outer Jacket Color

Marking (Printing in BLUE)

(xxmm=year of production+15 and month of production)

CY 3×2.5 mm² [MeterMark]

Bare Copper

0.25(+/-0.005)×50

2.04

FR-PVC

0.68

3.40+/-0.05

Blue, Brown, Yellow/Green

145mm

Right

>=125%

Tinned Copper

T0.12x16x10

51


FR-PVC

0.90

9.67±0.3

Grey(RAL7000)

Design

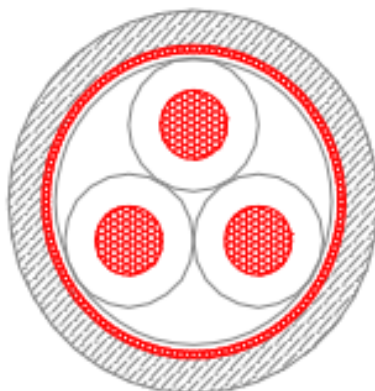

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	<7.98
Rated Temperature(°C)	80
Rated Voltage(V)	450/750
Min.Insulation DC Resistance at 20°C (M Ω *KM)	>500

RoHS GUIDELINE

We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls(PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	