
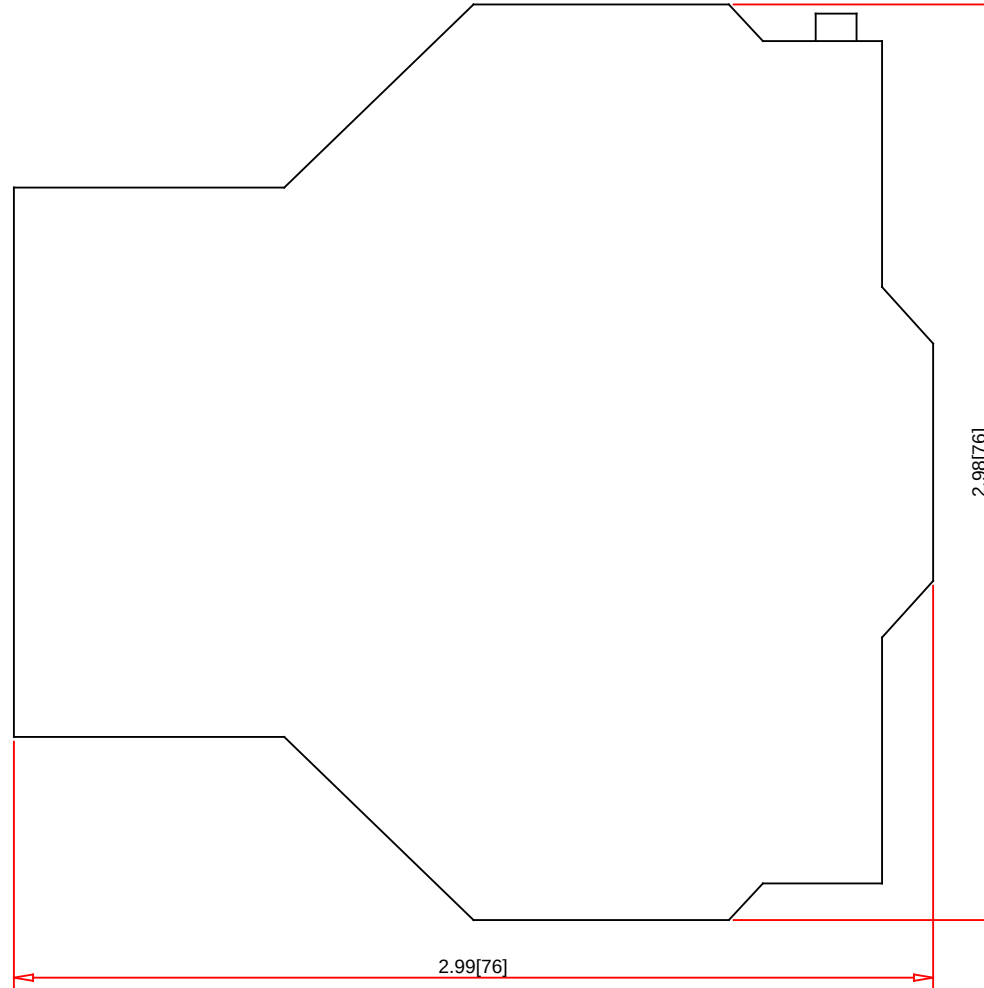


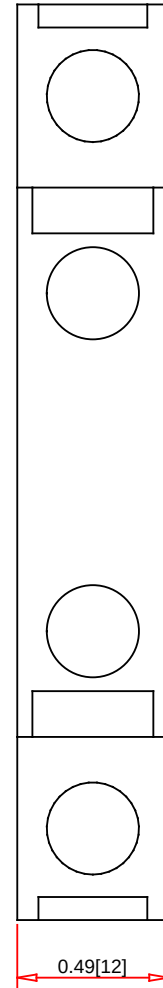

Note: - Drawings Not To Scale - Drawings Subject to Change Without Notice - Dimensions are inches next to [Millimeters]		Part No.: LAD8N11		Schneider Electric Schneider Electric United States North American Division Boston One Campus 800 Federal Street Andover, MA 01810, USA Phone: +1 8773425173 Email: CCC@us.schneider-electric.com	
Technical Information: Contact Rating: A600, Q600 10A UL File/CCN: E164862 / NKCR CSA File: LR43364 3211 04 Meets Standard: IEC 60947-5-1 Weight: 0.12 lb (0.05 kg) Termination Method: Screw Terminal Control Wire Size: #10 - #18 AWG Control Terminal Torque: 15 lb-in (1.7 Nm) Mounting Hardware: TeSys D IEC AC or DC Contactor or Control Relay				Description: TeSys D IEC Contact Block - Side Mount - 1NO, 1NC Type: TeSys D IEC Contactor and Control Relay Accessory	